

PCT 050705



Sample image

Order symbol : PCT 050705

Product nr : 7022521

Description : Enclosure, PC


Remarks : Clear transparent cover

EAN : 6418074003720

El. number :

- Finland : 3423524
- Denmark : 8212002539

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

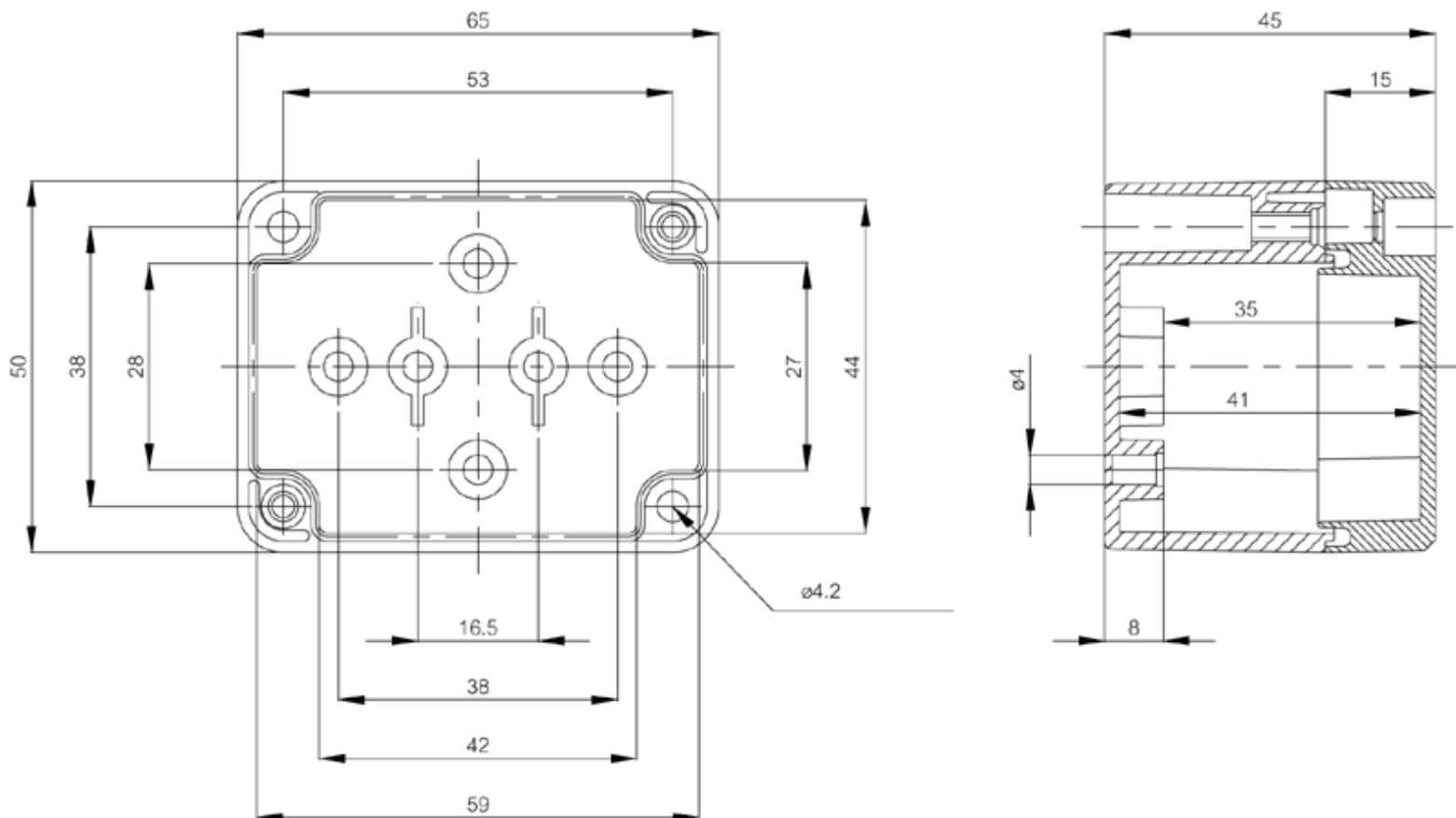

Dimensions :

	Height	Width	Depth
mm :	50	65	45
inch :	1.97	2.56	1.77

Accessories :

TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 0507	Mounting plate, for enclosures:

Materials :

Material :	Polycarbonate
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

(26 x 57 x 1)

TRM 0507	DIN-15 Mounting rail, for enclosures: (48 x 15 x 1)
TM 0505	Mounting plate, for enclosures: (26 x 48 x 1)
TH A	Grey plastic hinges (2 pcs)

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

SGSFimko_EURONORD