

# PCT 121207



Sample image

**Order symbol :** PCT 121207

**Product nr :** 7022661

**Description :** Enclosure, PC


**Remarks :** Clear transparent cover

**EAN :** 6418074005205

**El. number :**

- Finland : 3423533
- Denmark : 8212002759

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

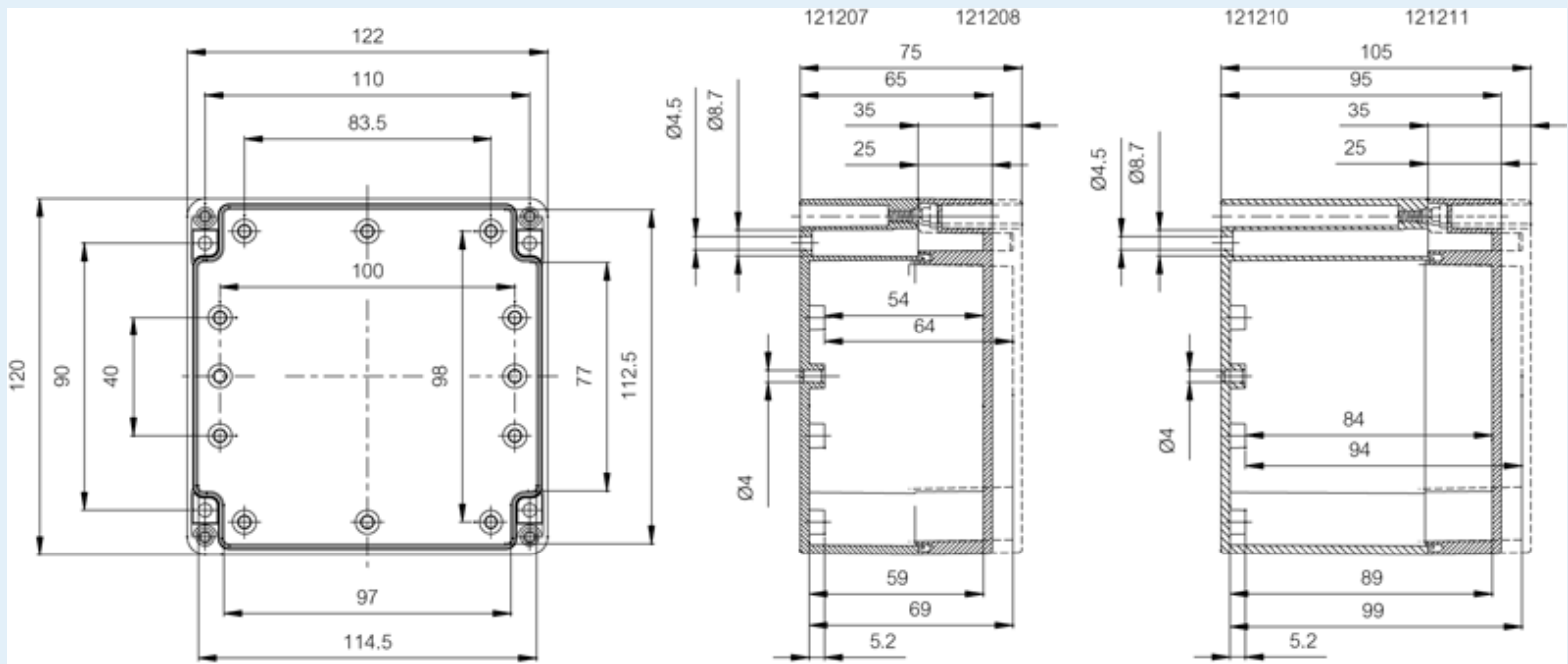

Dimensions :	Height	Width	Depth
mm :	120	122	65
inch :	4.72	4.8	2.56

**Materials :**

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent

**Accessories :**

TRH 1212	DIN-35 Mounting rail, for enclosures: (110 x 35 x 1)
TRM 0812	DIN-15 Mounting rail, for enclosures: (106 x 15 x 1)
TRM 1212	DIN-15 Mounting rail, for enclosures: (110 x 15 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 1212	Mounting plate, for enclosures: (96 x 111 x 1)

Gasket material : Polyurethane

TH A Grey plastic hinges (2 pcs)

**Temperatures :**

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

**Ratings :**

Ingress protection (EN 60529): IP66; IP67;  
Impact Resistance (EN 62262): IK07; IK08;  
electrical\_insulation : Totally insulated  
Halogen free (DIN/VDE 0472, Part 815) : Yes  
UV resistance : UL 746C  
Flammability Rating : UL 94 V0  
Glow Wire Test (IEC 695-2-1) °C : 960C

**Certificates :**

SGSFimko\_EURONORD