

PCT 121210



Sample image

Order symbol : PCT 121210

Product nr : 7022681

Description : Enclosure, PC


Remarks : Clear transparent cover

EAN : 6418074003775

El. number :

- Finland : 3423534
- Denmark : 8212002775

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

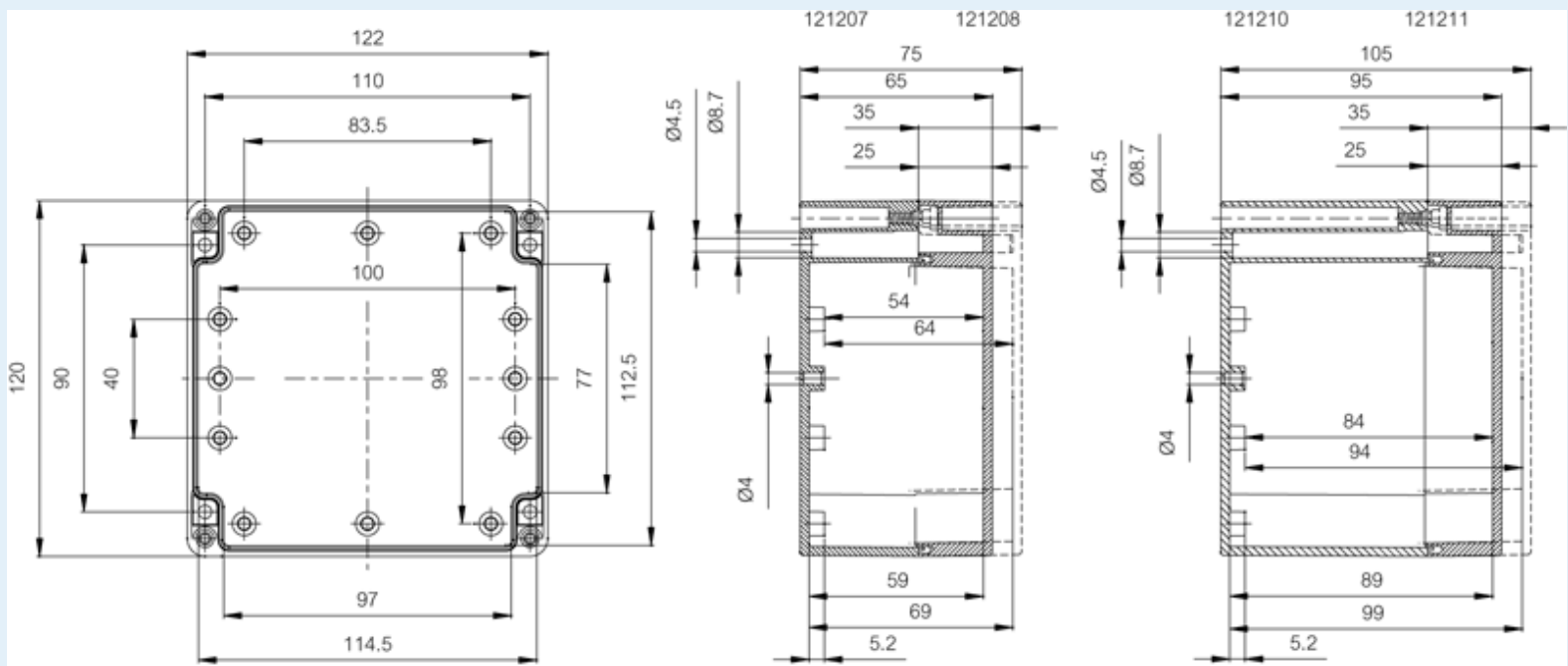

Dimensions :	Height	Width	Depth
mm :	120	122	95
inch :	4.72	4.8	3.74

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent

Accessories :

TRH 1212	DIN-35 Mounting rail, for enclosures: (110 x 35 x 1)
TRM 0812	DIN-15 Mounting rail, for enclosures: (106 x 15 x 1)
TRM 1212	DIN-15 Mounting rail, for enclosures: (110 x 15 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 1212	Mounting plate, for enclosures: (96 x 111 x 1)

Gasket material : Polyurethane

TH A Grey plastic hinges (2 pcs)

Temperatures :

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

Ratings :

Ingress protection (EN 60529): IP66; IP67;
Impact Resistance (EN 62262): IK07; IK08;
electrical_insulation : Totally insulated
Halogen free (DIN/VDE 0472, Part 815) : Yes
UV resistance : UL 746C
Flammability Rating : UL 94 V0
Glow Wire Test (IEC 695-2-1) °C : 960C

Certificates :

SGSFimko_EURONORD