

# PCT 121609



Sample image

**Order symbol :** PCT 121609

**Product nr :** 7022721

**Description :** Enclosure, PC


**Remarks :** Clear transparent cover

**EAN :** 6418074003782

**El. number :**

- Finland : 3423536
- Denmark : 8212002814

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

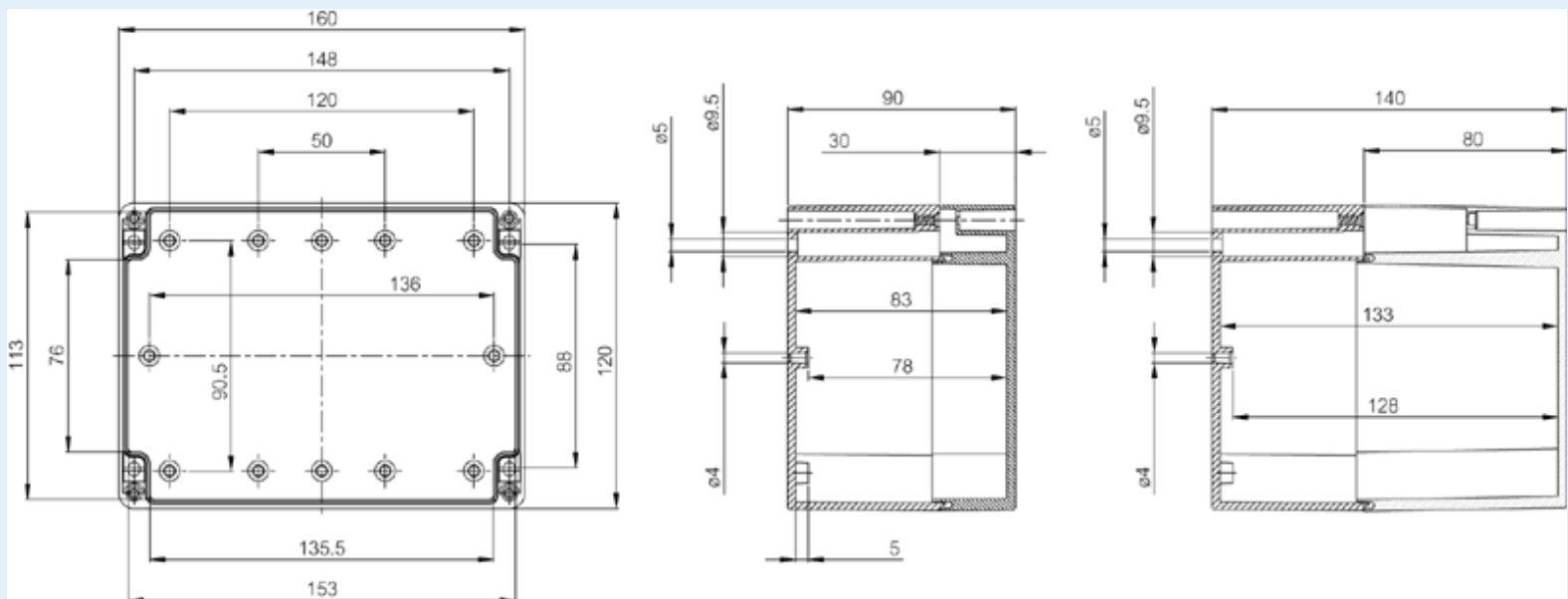

Dimensions :	Height	Width	Depth
mm :	120	160	90
inch :	4.72	6.3	3.54

## Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

## Accessories :

MIV 10	DIN-35 Mounting rail, for enclosures: (100 x 35 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TRH 1216	DIN-35 Mounting rail, for enclosures: (146 x 35 x 1)
TRM 0816	DIN-15 Mounting rail, for enclosures: (146 x 15 x 1)
TM 1216	Mounting plate, for enclosures: (111 x 134 x 1)
TH A	Grey plastic hinges (2 pcs)

**Temperatures :**

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

**Ratings :**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

**Certificates :**

SGSFimko\_EURONORD