

PCT 122008



Sample image

Order symbol : PCT 122008

Product nr : 7022761

Description : Enclosure, PC



Remarks : Clear transparent cover

EAN : 6418074003799

El. number :

- Finland : 3423538
- Denmark : 8212002856

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

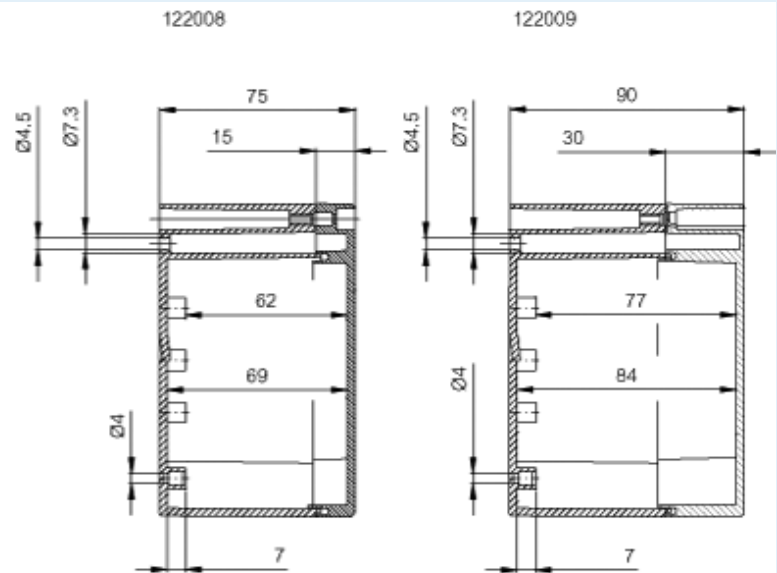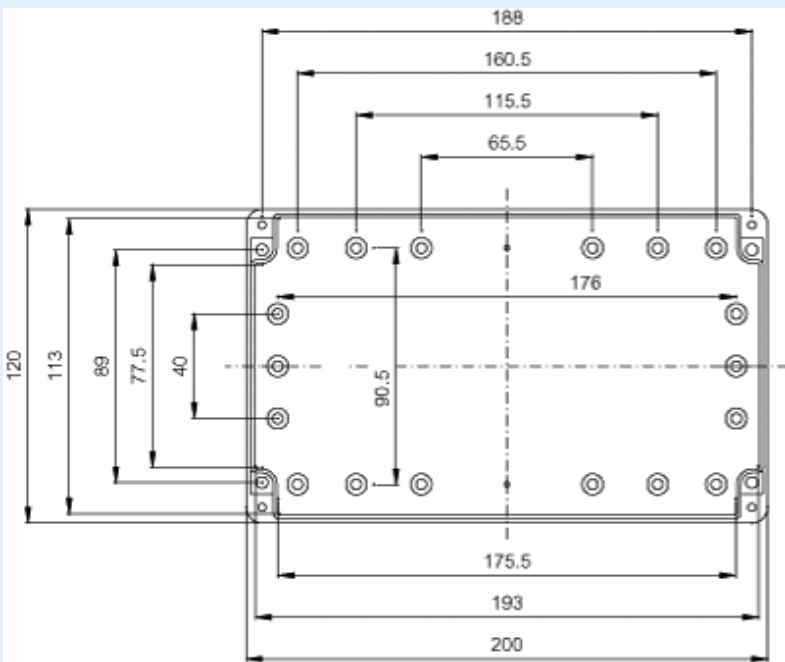

Dimensions :	Height	Width	Depth
mm :	120	200	75
inch :	4.72	7.87	2.95

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent

Accessories :

MIV 10	DIN-35 Mounting rail, for enclosures: (100 x 35 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TRH 1220	DIN-35 Mounting rail, for enclosures: (186 x 35 x 1)
TM 1220	Mounting plate, for enclosures: (111 x 174 x 2)
TH A	Grey plastic hinges (2 pcs)

Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

Ratings :

Ingress protection (EN 60529): IP66; IP67;

Impact Resistance (EN 62262): IK07; IK08;

electrical_insulation : Totally insulated

Halogen free (DIN/VDE 0472, Part 815) : Yes

UV resistance : UL 746C

Flammability Rating : UL 94 V0

Glow Wire Test (IEC 695-2-1) °C : 960C

Certificates :

SGSFimko_EURONORD