

# PCT 122009



Sample image

**Order symbol :** PCT 122009

**Product nr :** 7022771

**Description :** Enclosure, PC


**Remarks :** Clear transparent cover

**EAN :** 6418074058638

**El. number :**

- Finland : 3435406
- Denmark : 8212003156

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

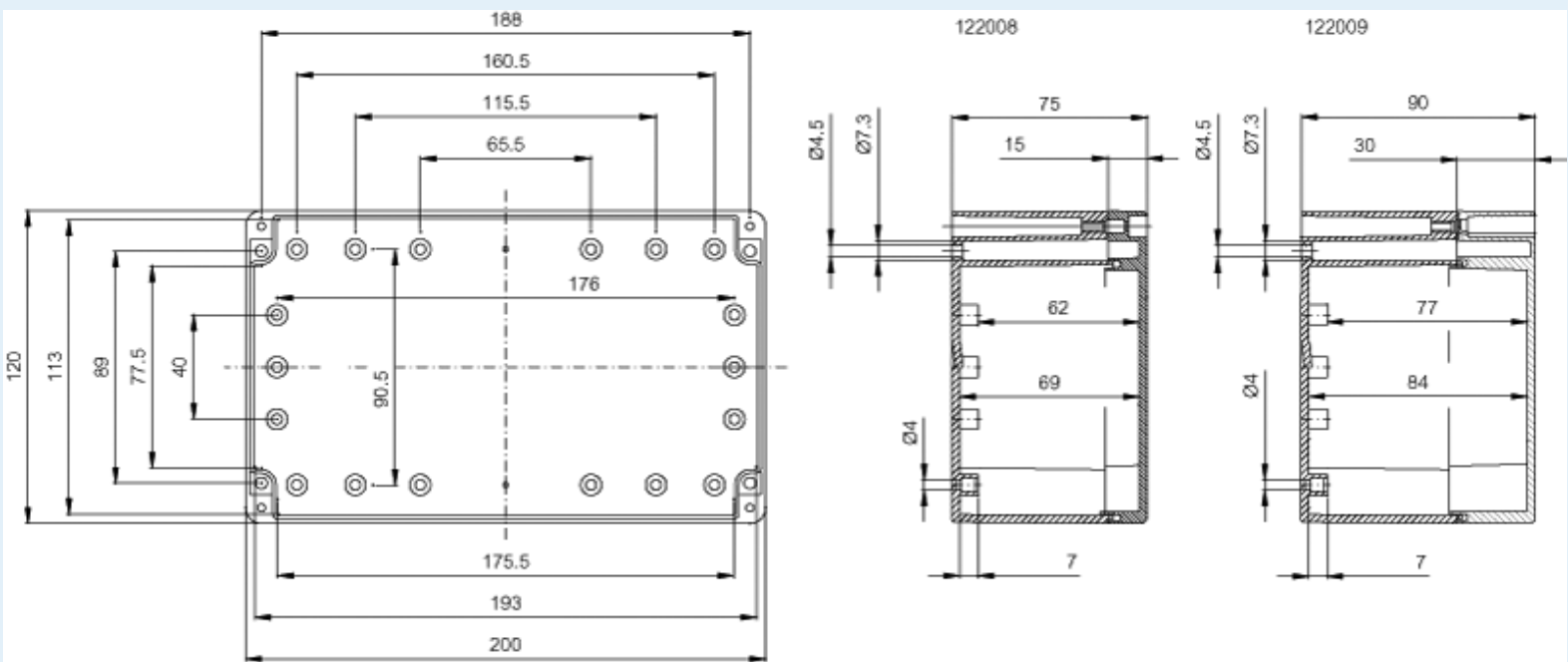

Dimensions :	Height	Width	Depth
mm :	120	200	90
inch :	4.72	7.87	3.54

**Materials :**

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent

**Accessories :**

MIV 10	DIN-35 Mounting rail, for enclosures: (100 x 35 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TRH 1220	DIN-35 Mounting rail, for enclosures: (186 x 35 x 1)
TM 1220	Mounting plate, for enclosures: (111 x 174 x 2)
TH A	Grey plastic hinges (2 pcs)

Gasket material : Polyurethane

**Temperatures :**

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

**Ratings :**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

**Certificates :**

SGSFimko\_EURONORD