

PCT 152008

FIBOX
Enclosing innovations



Sample image

Order symbol : PCT 152008

Product nr : 7022821

Description : Enclosure, PC



Remarks : Clear transparent cover

EAN : 6418074010643

El. number :

- Finland : 3423539
- Denmark : 8212002872

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

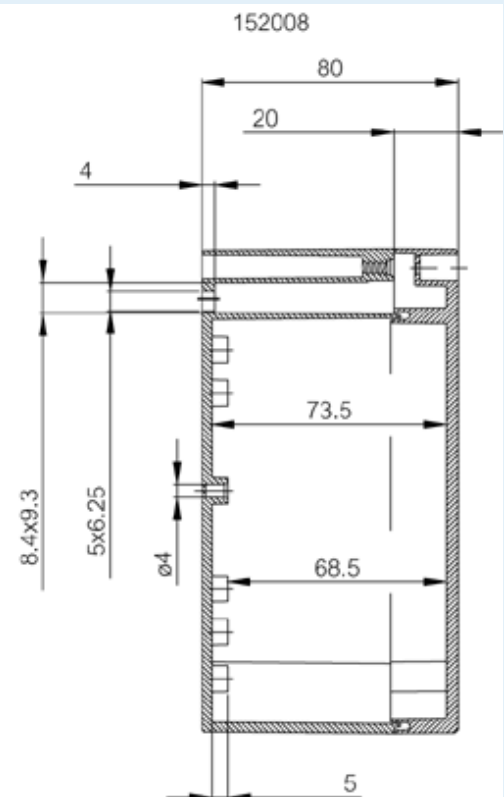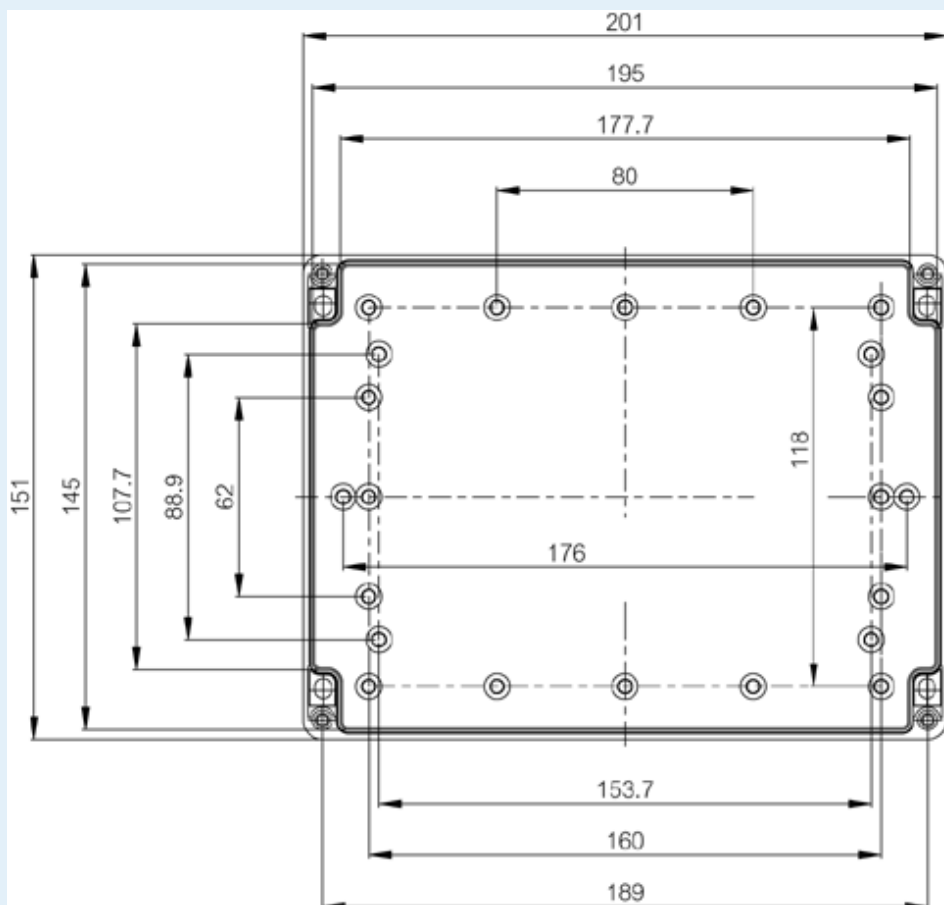

Dimensions :

	Height	Width	Depth
mm :	150	201	80
inch :	5.91	7.91	3.15

Accessories :

TF 28037	Wall fastening lug (4 pcs), for enclosures:
TRH 1220	DIN-35 Mounting rail, for enclosures:

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

(186 x 35 x 1)

TM 1520	Mounting plate, for enclosures: (141 x 174 x 1)
TH A	Grey plastic hinges (2 pcs)

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

SGSFimko_EURONORD