

PCT 163610



Sample image

Order symbol : PCT 163610

Product nr : 7022851

Description : Enclosure, PC


Remarks : Clear transparent cover

EAN : 6418074058706

El. number :

- Finland : 3435420
- Denmark : 8212003172

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

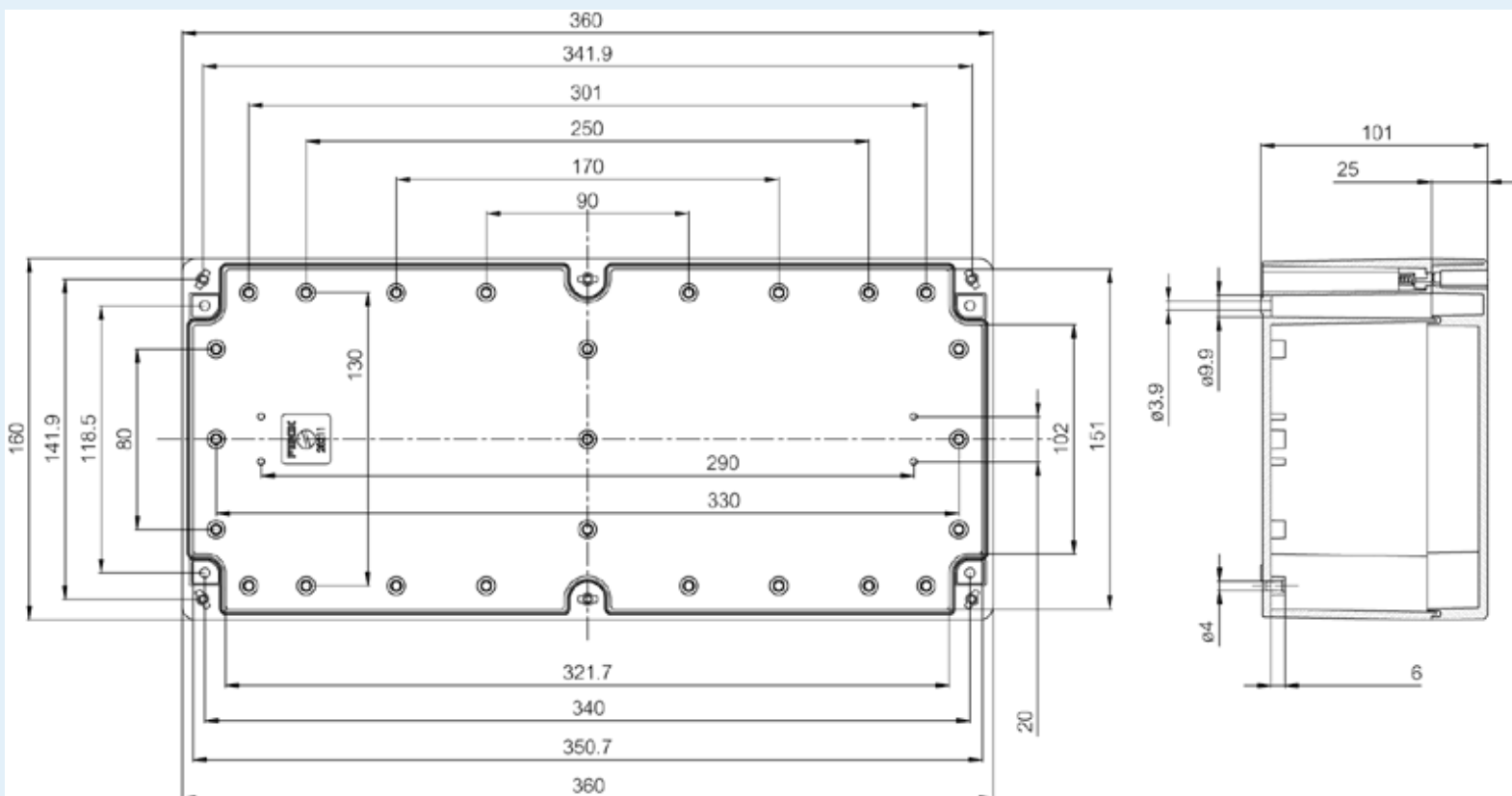

Dimensions :

	Height	Width	Depth
mm :	160	360	100
inch :	6.3	14.17	3.94

Accessories :

TF 28037	Wall fastening lug (4 pcs), for enclosures:
ARM 0615	DIN-15 Mounting rail, for enclosures: (140 x 15 x 1)
TM 1636	Mounting plate, for enclosures:

Materials :	
Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

Temperatures :	
Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

	(318 x 146 x 1)
DH-3	DIN-35 Mounting rail, for enclosures: (140 x 35 x 1)
TH A	Grey plastic hinges (2 pcs)
TRH 2036	DIN-35 Mounting rail, for enclosures: (35 x 340 x 1)

Ratings :	
Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :	
SGSFimko_EURONORD	