

# PC 050705 enclosure



Sample image

**Order symbol :** PC 050705 enclosure

**Product nr :** 7032520

**Description :** Enclosure, PC


**Remarks :** Grey cover

**EAN :** 6418074003607

**El. number :**

- Finland : 3423424
- Denmark : 8212002526
- Sweden : 2536105

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

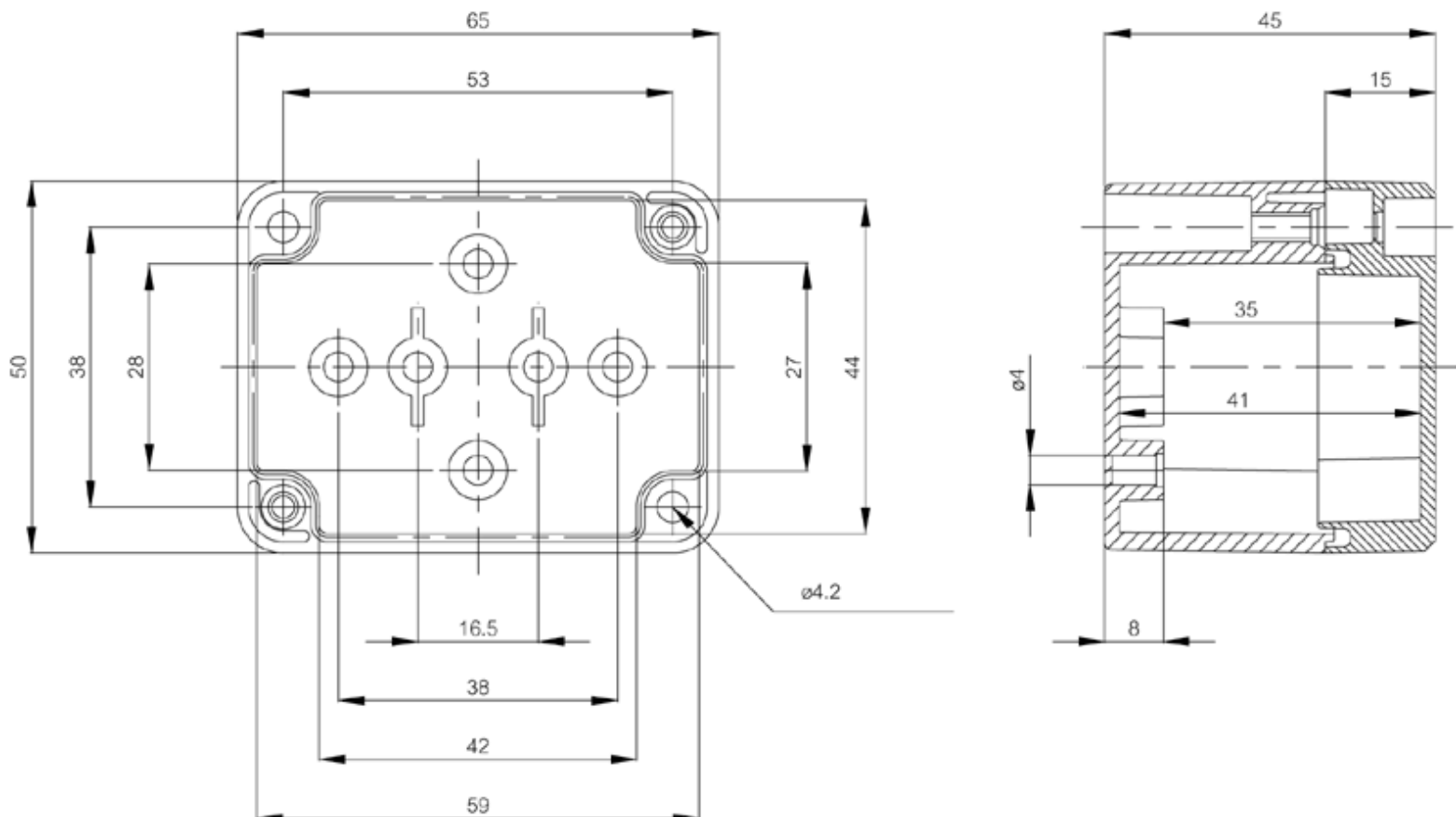

**Dimensions :**

**Height**

**Width**

**Depth**

**Accessories :**

mm :	50	65	45
inch :	1.97	2.56	1.77

#### Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

#### Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 0507	Mounting plate, for enclosures: (26 x 57 x 1)
TRM 0507	DIN-15 Mounting rail, for enclosures: (48 x 15 x 1)
TM 0505	Mounting plate, for enclosures: (26 x 48 x 1)
TH A	Grey plastic hinges (2 pcs)

#### Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

#### Certificates :

SGSFimko\_EURONORD