

# PC 071004



Sample image

**Order symbol :** PC 071004

**Product nr :** 7032530

**Description :** Enclosure, PC


**Remarks :** Grey cover

**EAN :** 6418074058300

**El. number :**

- Finland : 3435340
- Denmark : 8212002542
- Sweden : 2536106

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

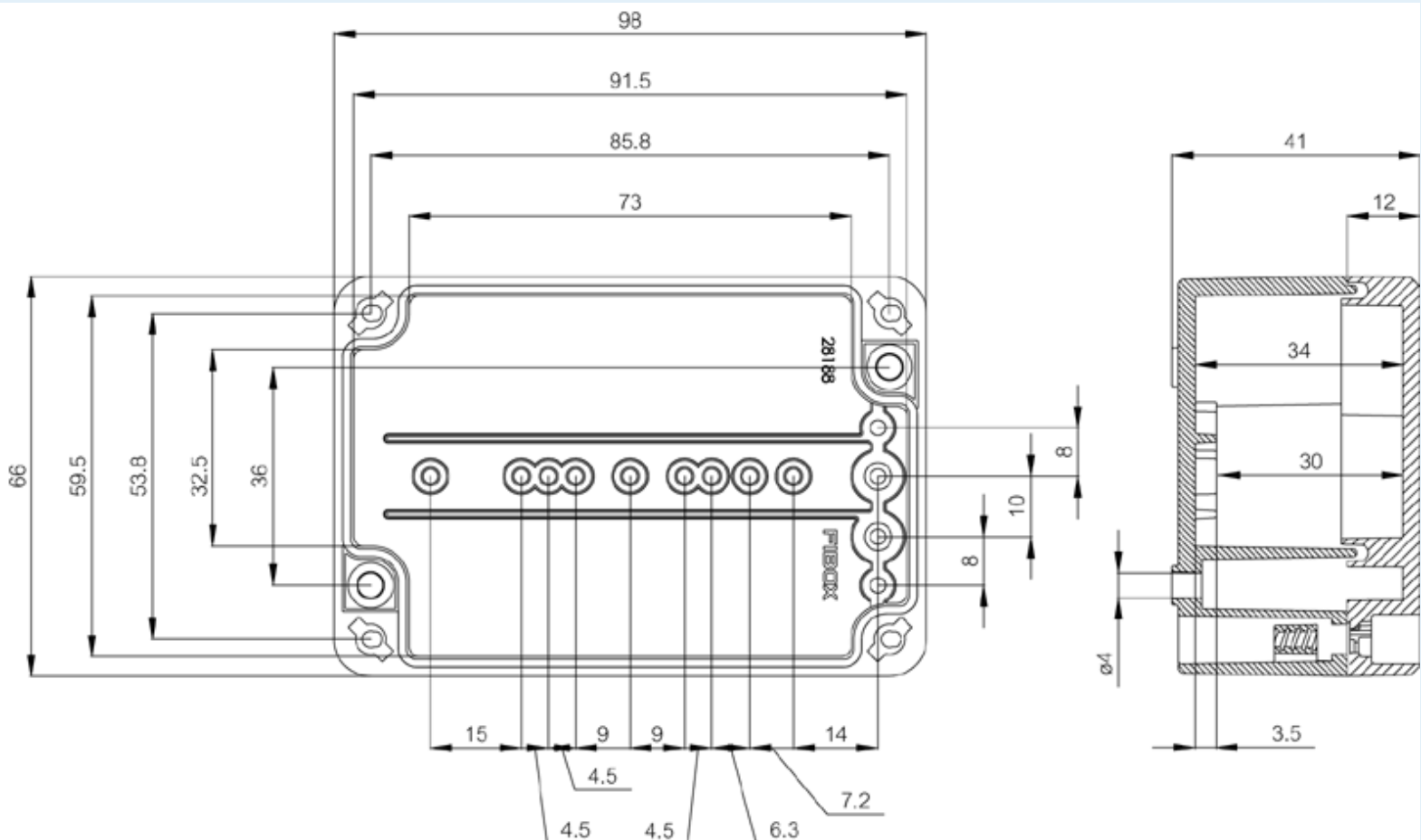

**Dimensions :**

mm :

**Height**

66

**Width**

98

**Depth**

41

**Accessories :**

TF 28037 Wall fastening lug (4 pcs), for enclosures:

inch : 2.6 3.86 1.61

TH A Grey plastic hinges (2 pcs)

**Materials :**

Material : Polycarbonate  
Base colour : RAL\_7035  
Cover colour : RAL 7035 -light grey  
Gasket material : Polyurethane

**Temperatures :**

Temperature °C (continuous) : -40 ... 80  
Temperature °F (continuous) : -40 ... 175

**Ratings :**

Ingress protection (EN 60529): IP66; IP67;  
Impact Resistance (EN 62262): IK07; IK08;  
electrical\_insulation : Totally insulated  
Halogen free (DIN/VDE 0472, Part 815) : Yes  
UV resistance : UL 746C  
Flammability Rating : UL 94 V0  
Glow Wire Test (IEC 695-2-1) °C : 960C

**Certificates :**

SGSFimko\_EURONORD