

# PC 080806



Sample image

**Order symbol :** PC 080806

**Product nr :** 7032540

**Description :** Enclosure, PC


**Remarks :** Grey cover

**EAN :** 6418074058317

**El. number :**

- Finland : 3435342
- Denmark : 8212002568
- Sweden : 2536107

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

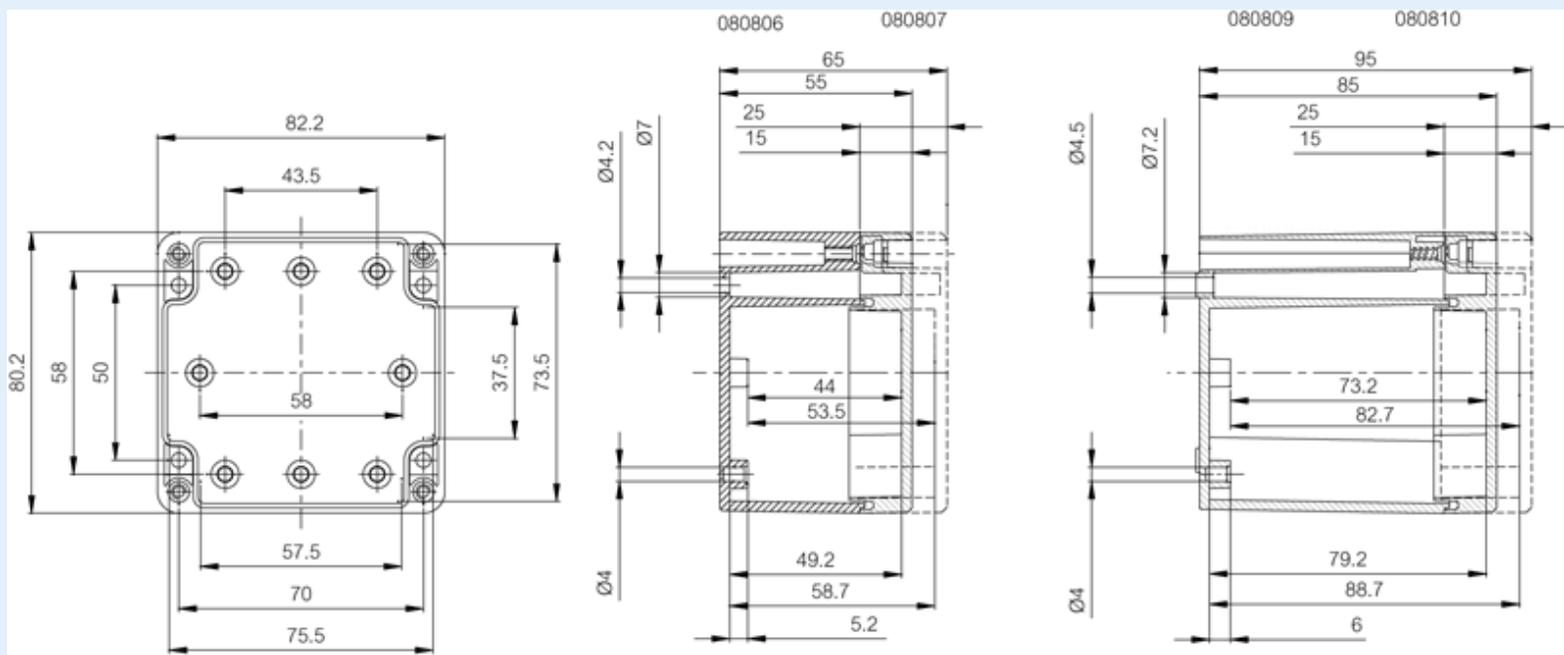

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 80     | 82    | 55    |
| inch :       | 3.15   | 3.23  | 2.17  |

## Materials :

|                |                      |
|----------------|----------------------|
| Material :     | Polycarbonate        |
| Base colour :  | RAL_7035             |
| Cover colour : | RAL 7035 -light grey |

## Accessories :

|          |  |
|----------|--|
| TF 28037 | Wall fastening lug (4 pcs), for enclosures:            |
| TM 0808  | Mounting plate, for enclosures:<br>(56 x 71 x 1)       |
| TH A     | Grey plastic hinges (2 pcs)                            |
| TRM 0808 | DIN-15 Mounting rail, for enclosures:<br>(68 x 15 x 1) |

## Ratings :

Gasket material : Polyurethane

**Temperatures :**

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

Ingress protection (EN 60529): IP66; IP67;  
Impact Resistance (EN 62262): IK07; IK08;  
electrical\_insulation : Totally insulated  
Halogen free (DIN/VDE 0472, Part 815) : Yes  
UV resistance : UL 746C  
Flammability Rating : UL 94 V0  
Glow Wire Test (IEC 695-2-1) °C : 960C

**Certificates :**

SGSFimko\_EURONORD