

PC 081209

FIBOX
Enclosing innovations



Sample image

Order symbol : PC 081209

Product nr : 7032600

Description : Enclosure, PC


Remarks : Grey cover

EAN : 6418074058355

El. number :

- Finland : 3435350
- Denmark : 8212003088
- Sweden : 2536112

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

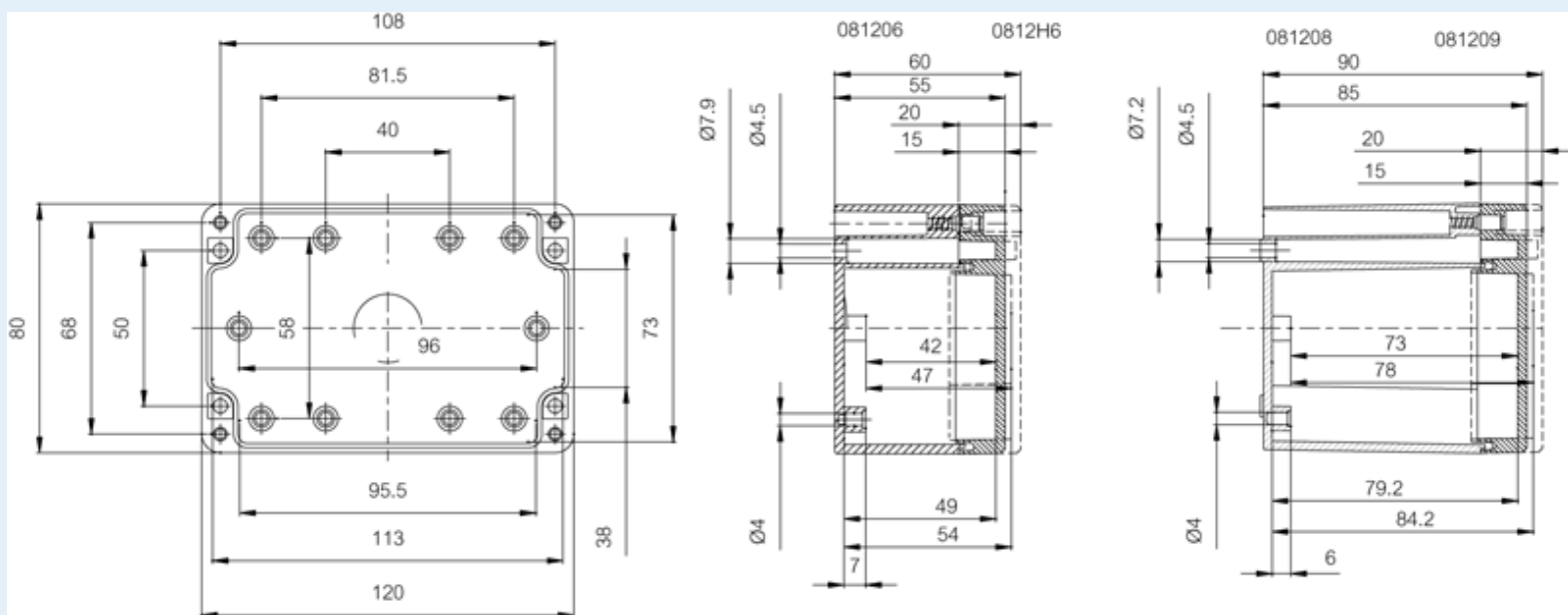

Dimensions :	Height	Width	Depth
mm :	80	120	85
inch :	3.15	4.72	3.35

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Accessories :

TRM 0812	DIN-15 Mounting rail, for enclosures: (106 x 15 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 0812	Mounting plate, for enclosures: (71 x 94 x 1)
ARH 12	DIN-35 Mounting rail, for enclosures: (105 x 35 x 1)
TH A	Grey plastic hinges (2 pcs)
TRM 0808	DIN-15 Mounting rail, for enclosures: (68 x 15 x 1)

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

SGSFimko_EURONORD