

PC 122009



Sample image

Order symbol : PC 122009

Product nr : 7032770

Description : Enclosure, PC



Remarks : Grey cover

EAN : 6418074058423

El. number :

- Finland : 3435364
- Denmark : 8212003143
- Sweden : 2536126

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

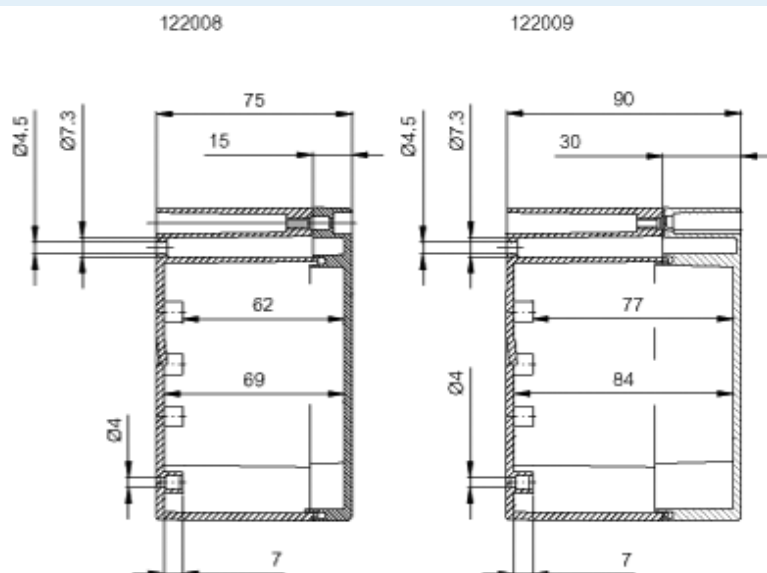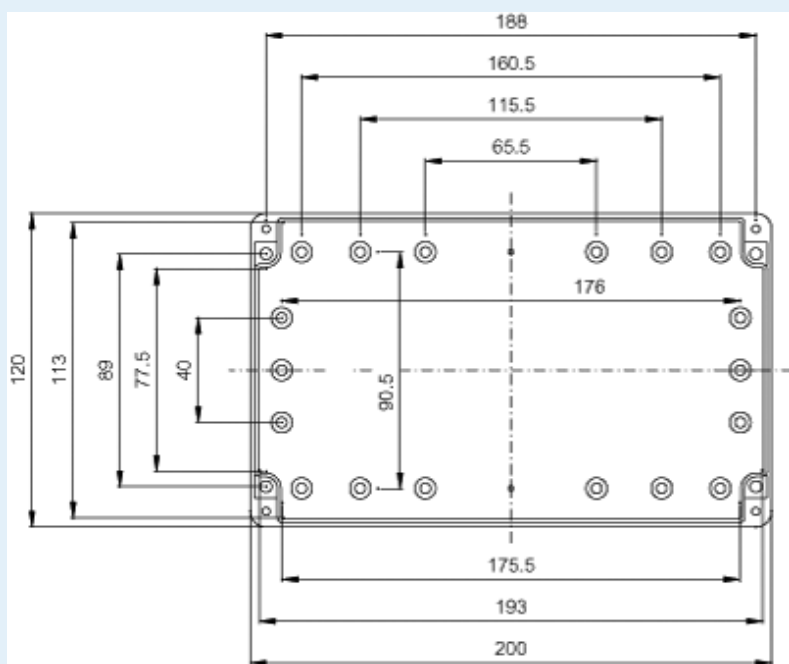

Dimensions :	Height	Width	Depth
mm :	120	200	90
inch :	4.72	7.87	3.54

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey

Accessories :

MIV 10	DIN-35 Mounting rail, for enclosures: (100 x 35 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TRH 1220	DIN-35 Mounting rail, for enclosures: (186 x 35 x 1)
TM 1220	Mounting plate, for enclosures: (111 x 174 x 2)
TH A	Grey plastic hinges (2 pcs)

Gasket material :	Polyurethane
-------------------	--------------

Temperatures :	
Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Ratings :	
Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :	
SGSFimko_EURONORD	