

ABS 1919 13 G



Sample image

Order symbol : ABS 1919 13 G

Product nr : 5880359

Description : Enclosure, ABS


Remarks : Grey cover

Including : Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

EAN : 6418074039002

El. number :

- Finland : 3423751
- Denmark : 8212050510
- Sweden : 2539705

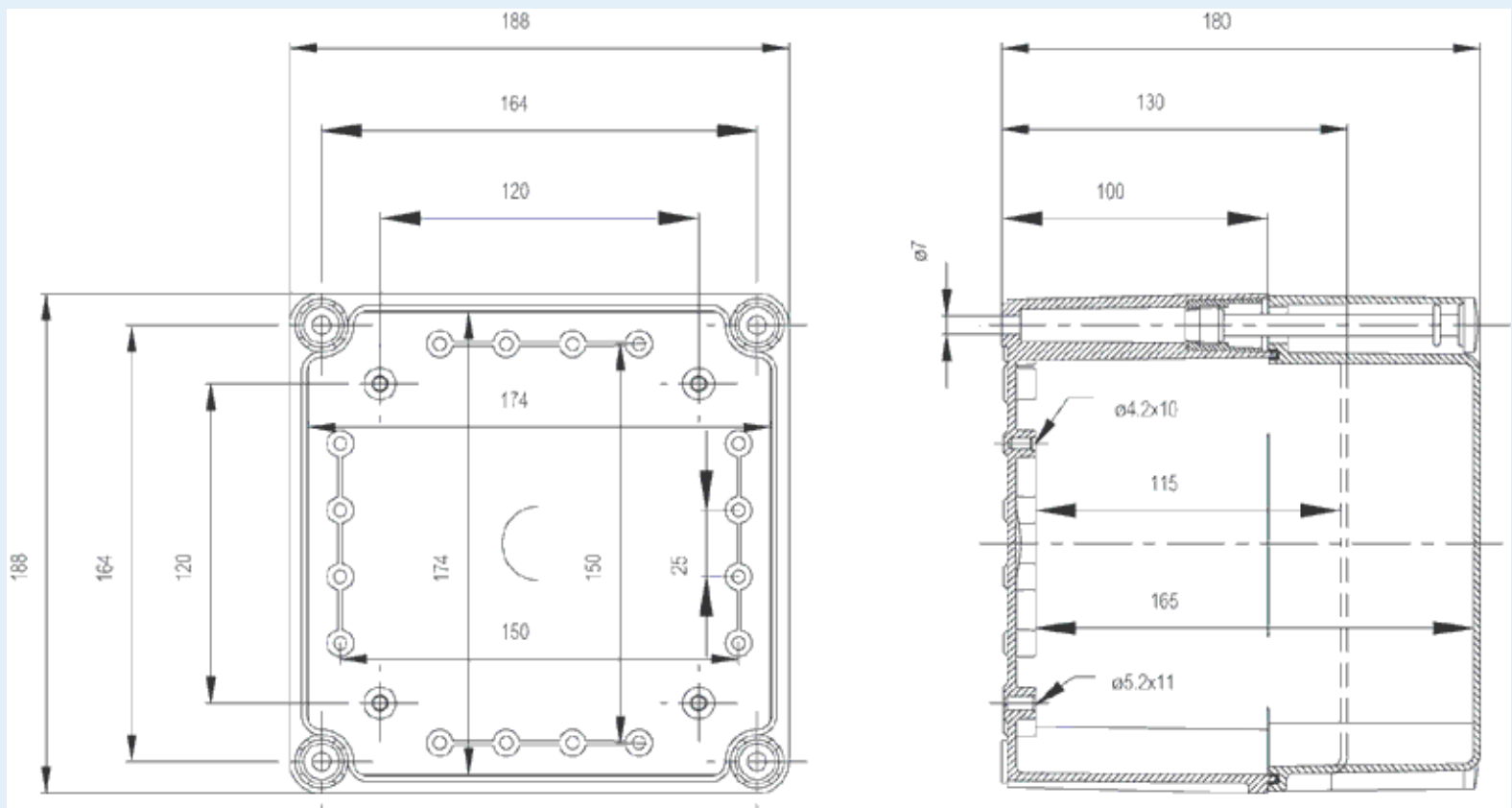

Dimensions :	Height	Width	Depth
mm :	190	190	130
inch :	7.48	7.48	5.12

Accessories :

EKHVT	Mounting plate, for enclosures: (148 x 148 x 1)
EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)

Materials :

Material :	ABS
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 60
Temperature °F (continuous) :	-40 ... 140

MPI EKH 1919 Multiperforated plastic mounting plate
(167 x 167 x 4)

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	-
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	650C

Certificates :

DSS_FI_41597_A1