

ABS 95/60 HG



Sample image

Order symbol : ABS 95/60 HG

Product nr : 6081331

Description : Enclosure, ABS


Remarks : High base, grey cover

EAN : 6418074054715

El. number :

- Finland : 3421380
- Denmark : 8212023987
- Sweden : 6081331

Including : Base with PUR gasket. screws for mounting plate/DIN-rail and cover with polyamide cover screws.

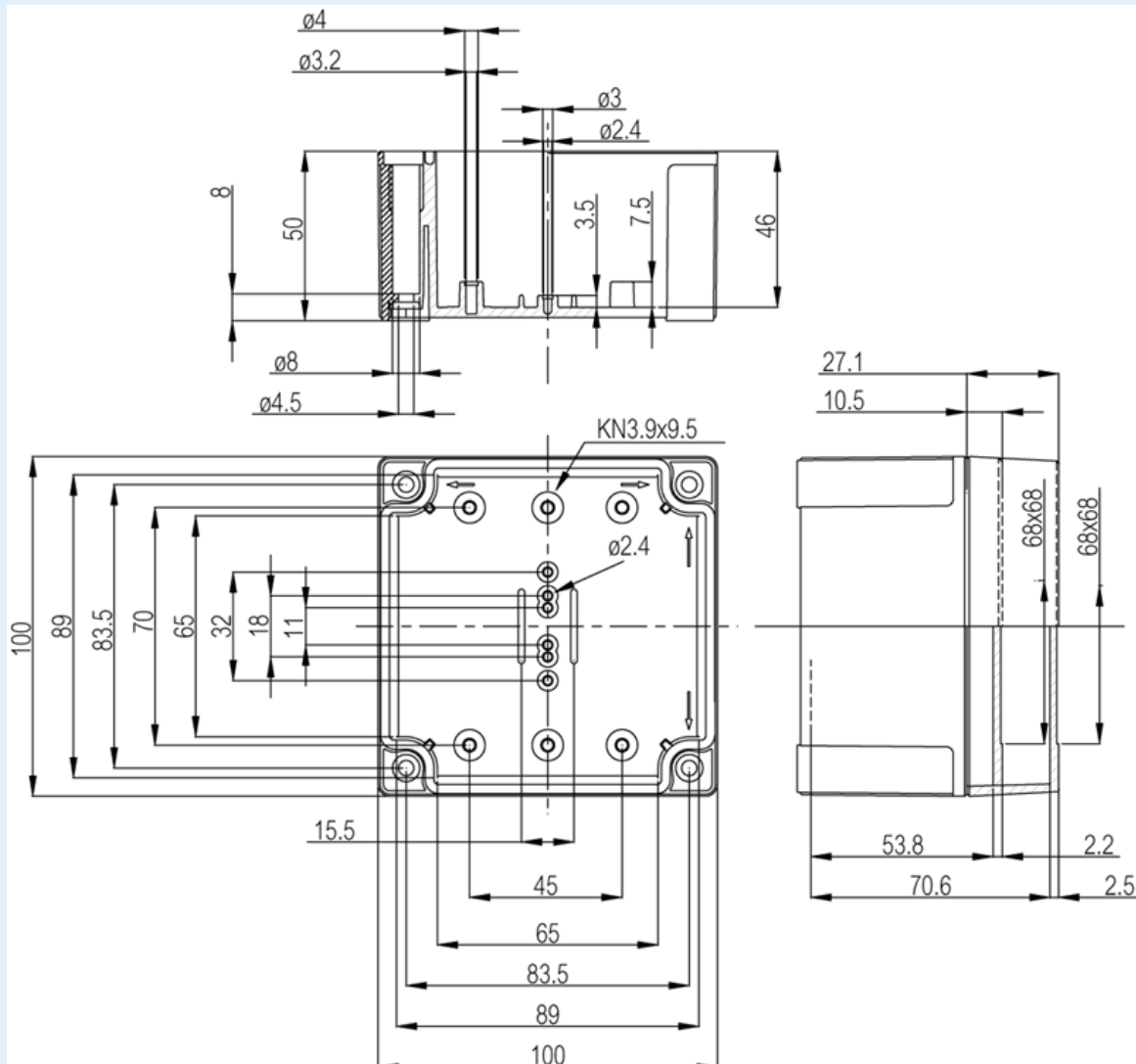

Dimensions :	Height	Width	Depth
mm :	100	100	60
inch :	3.94	3.94	2.36

Materials :	
Material :	ABS
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :	
Temperature °C (continuous) :	-40 ... 60
Temperature °F (continuous) :	-40 ... 140

Accessories :	
MIN 8	DIN-15 Mounting rail, for enclosures:
B-3	DIN-35 Mounting rail, for enclosures: (80 x 35 x 1)
FP 22046	Wall fastening lug (4 pcs)
MIV 95	Mounting plate (Galvanized steel), for enclosures: (66 x 80 x 1)

Ratings :	
Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	-
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	650C

Certificates :	
Certificate FI 41115	