

# NEO ABS 322215 G

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol :** NEO ABS 322215 G

**Product nr :** 4812000

UL Code : -

**Description :** Hinged ABS enclosure with grey cover


**Remarks :** -

**EAN :** 6418074311436

**El. number :**

- Finland : 3424417
- Denmark : 8212098080
- Sweden : 2506221

**Including :** ABS base and cover, mounting screws for mountingplate/DIN rail.

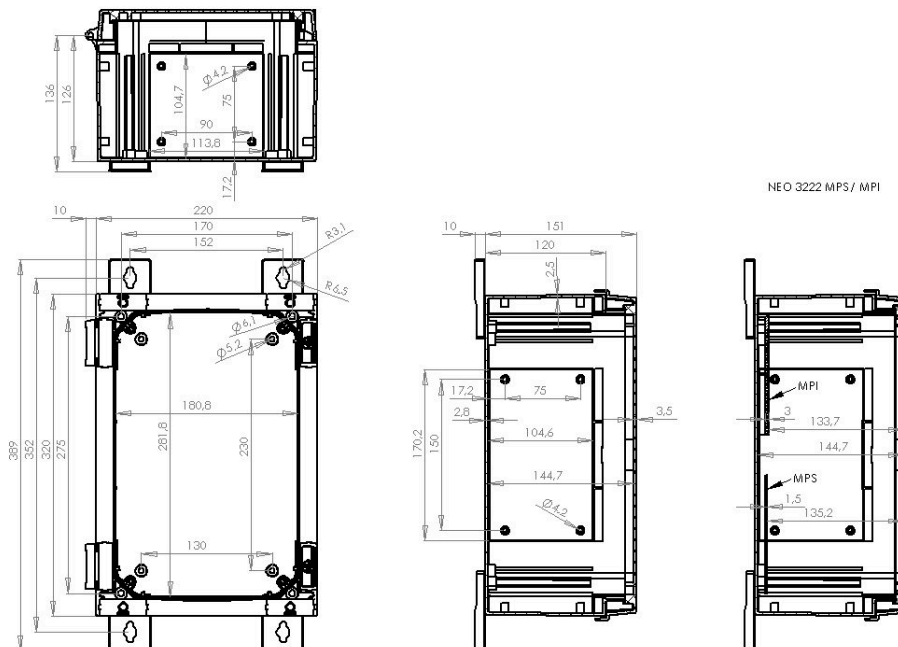

**Dimensions :**

	Height	Width	Depth
mm :	320	220	150
inch :	12.6	8.66	5.91

**Accessories :**

NEO MPI 3222	Multiperforated plastic mounting plate (275 x 165 x 3)
--------------	--

**Materials :**

Material :	ABS
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

NEO MPS 3222	Metal mounting plate (275 x 165 x 1)
PMK NEO 20	Polemounting kit (300 x 200 x 30)
WMK NEO plastic	Wall mounting kit plastic (80 x 70 x 40)
DRS NEO 322215	DIN rail frame set

**Temperatures :**

Temperature °C (continuous) :	-40 ... 60
Temperature °F (continuous) :	-40 ... 140

**Ratings :**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	-
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	650C

**Certificates :**

Certificate FI 40693 A1.pdf