

PCM 150/60 G

FIBOX
Enclosing innovations



Sample image

Order symbol : PCM 150/60 G

EAN : 6418074038074

Product nr : 6016313

El. number :


UL Name : UL PCM 150/60 G

- Finland : 3421640
- Denmark : 8212027145
- Sweden : 2535324

Description : Enclosure, PC, metric knock-outs

Remarks : Grey cover

Including : Base with TPE gasket. screws for mounting plate/DIN-rail and cover with polyamide cover screws.

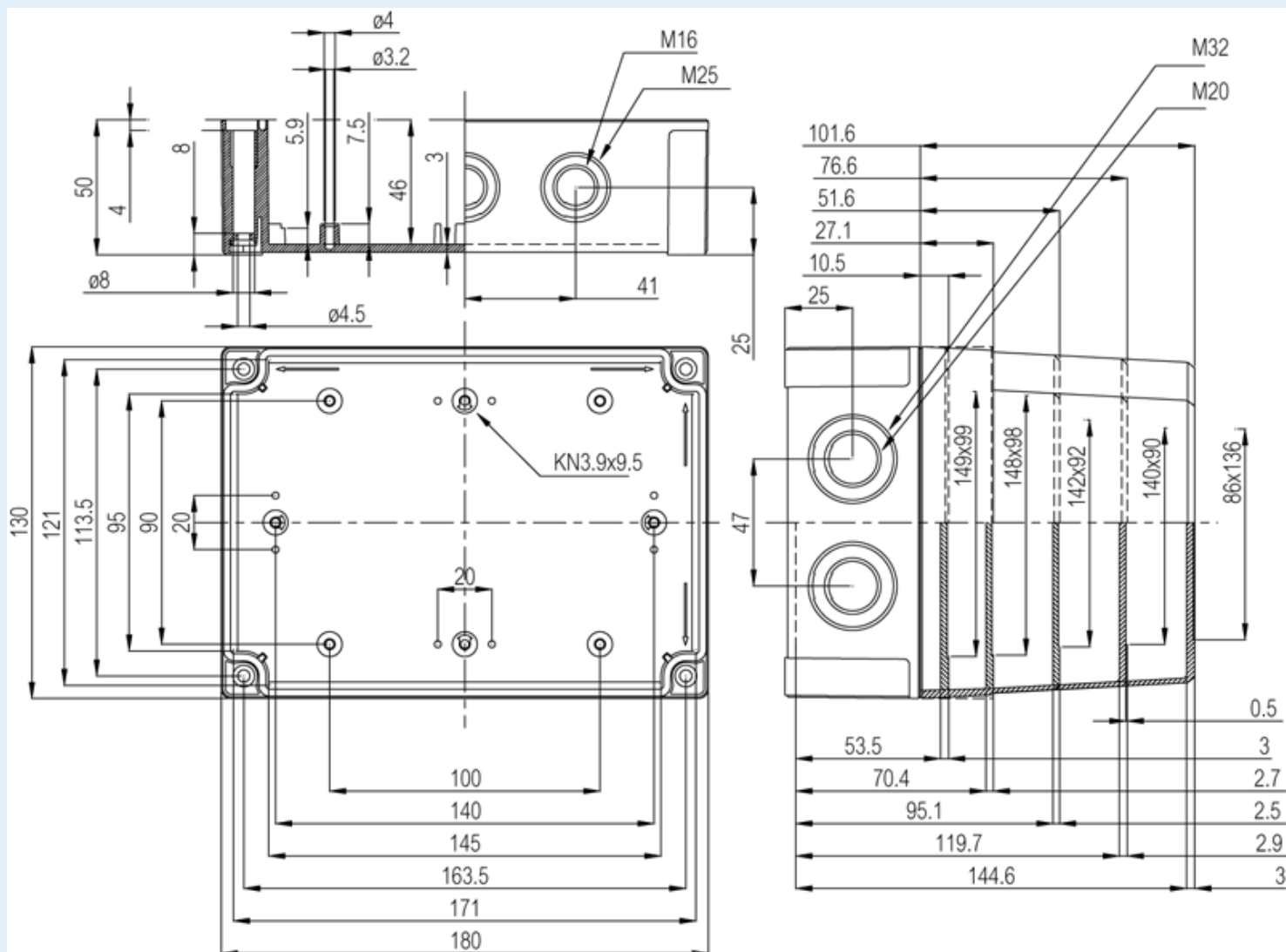

Dimensions :	Height	Width	Depth
mm :	180	130	60
Materials :			
Material :	Polycarbonate		
Base colour :	RAL_7035		
Cover colour :	RAL 7035 -light grey		
Gasket material :	Polyurethane		
Temperatures :			
Temperature °C (continuous) :	-40 ... 80		
Temperature °F (continuous) :	-40 ... 175		

Accessories :	
MIV 10	DIN-35 Mounting rail, for enclosures: (100 x 35 x 1)
FP A 150/180	Front plate (Aluminium), for enclosures: (170 x 112 x 1)
HFP 180	Front plate hinge series
MIV 150	Mounting plate (Galvanized steel), for enclosures: (148 x 98 x 1)
MIN 15	DIN-15 Mounting rail, for enclosures: (150 x 15 x 1)
MIN 10	DIN-15 Mounting rail, for enclosures:
MIV 15	DIN-35 Mounting rail, for enclosures: (150 x 35 x 1)
FP 22046	Wall fastening lug (4 pcs)

Ratings :	
Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :
Certificate FI 40847