

# PC 2819 13 G



Sample image

**Order symbol :** PC 2819 13 G

**Product nr :** 5330360

**Description :** Enclosure, PC


**Remarks :** Grey cover

**EAN :** 6418074005441

**El. number :**

- Finland : 3423705
- Denmark : 8212049259
- Sweden : 2539410

**Including :** Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

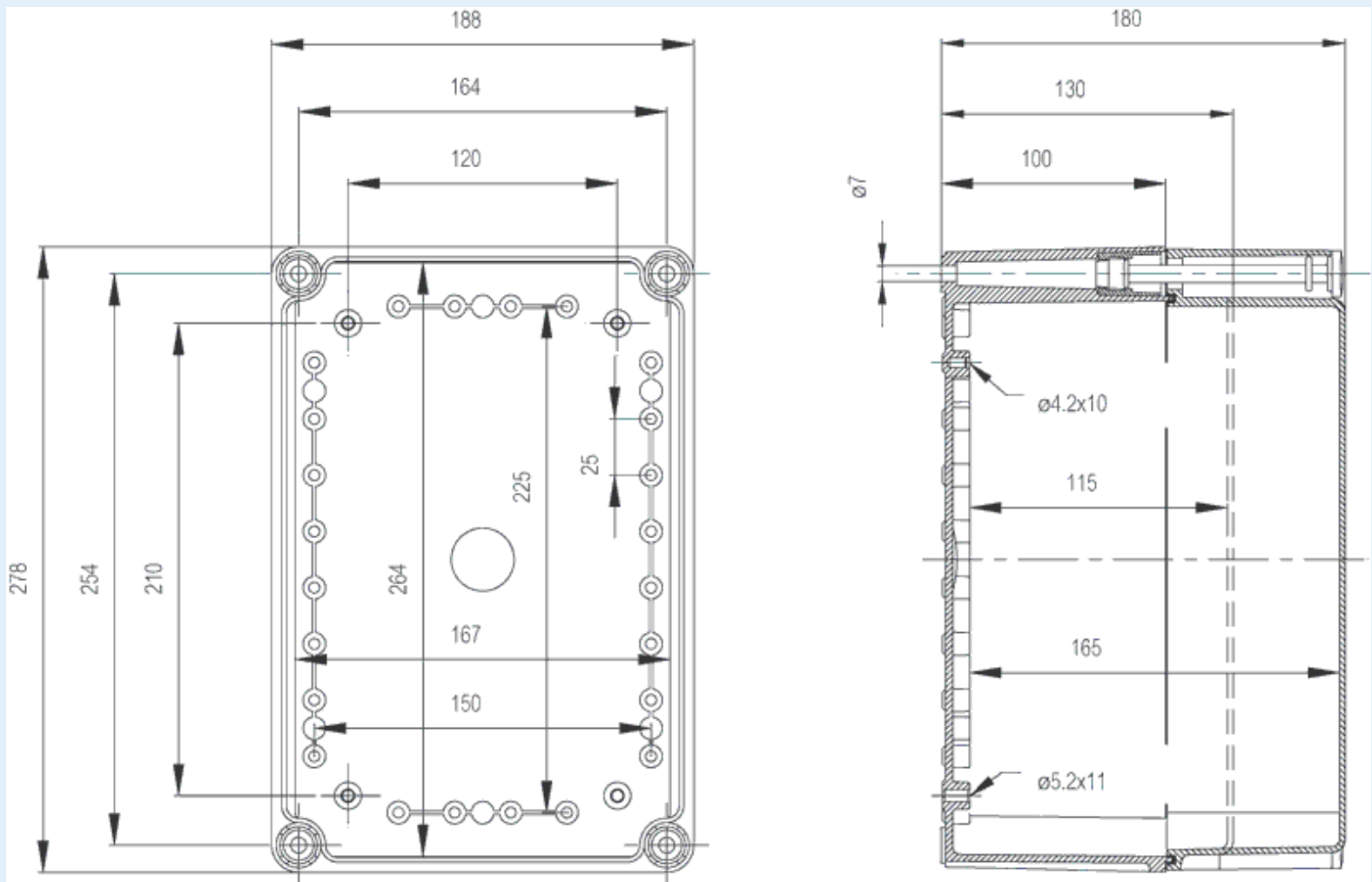

**Dimensions :**

	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	280	190	130
inch :	11.02	7.48	5.12

**Materials :**

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

**Temperatures :**

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

**Accessories :**

EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)
EKJVT	Mounting plate, for enclosures: (238 x 148 x 1)
EKV 22	DIN-35 Mounting rail, for enclosures: (235 x 35 x 1)
EKJZR	Extension frame, for enclosures: (280 x 190 x 50)
MPI EKJ 2819	Multiperforated plastic mounting plate (259 x 164 x 4)

**Ratings :**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

**Certificates :**

DSS\_FI\_41597\_A1