

PC 2819 18 G



Sample image

Order symbol : PC 2819 18 G

Product nr : 5330370

UL Name : UL PC 2819 18 G

Description : Enclosure, PC


Remarks : Grey cover

EAN : 6418074005465

El. number :

- Finland : 3423707
- Denmark : 8212051593
- Sweden : 2539412

Including : Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

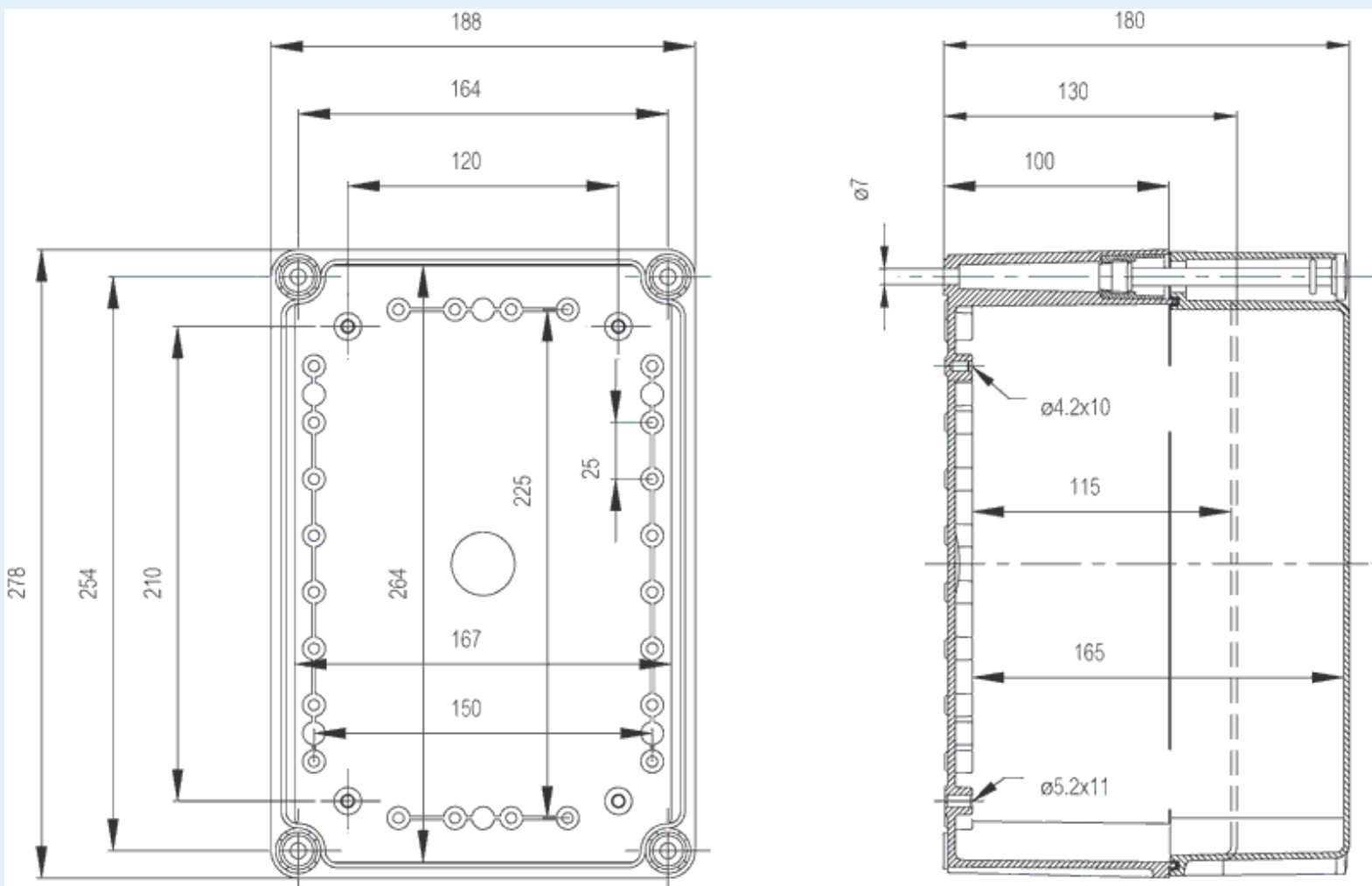

Dimensions :	Height	Width	Depth
mm :	280	190	180
inch :	11.02	7.48	7.09

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)
EKJVT	Mounting plate, for enclosures: (238 x 148 x 1)
EKV 22	DIN-35 Mounting rail, for enclosures: (235 x 35 x 1)
EKJZR	Extension frame, for enclosures: (280 x 190 x 50)
MPI EKJ 2819	Multiperforated plastic mounting plate (259 x 164 x 4)

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

DSS_FI_41597_A1