

PC 5638 18 G-3FSH



Sample image

Order symbol : PC 5638 18 G-3FSH

Product nr : 2539527

Description : Enclosure, PC

Remarks : Grey hinged cover


EAN : 6418074052810

El. number :

- Finland : 3435744
- Denmark : 8212051894
- Sweden : 2539527

Including : Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

SOLID 558x378x180

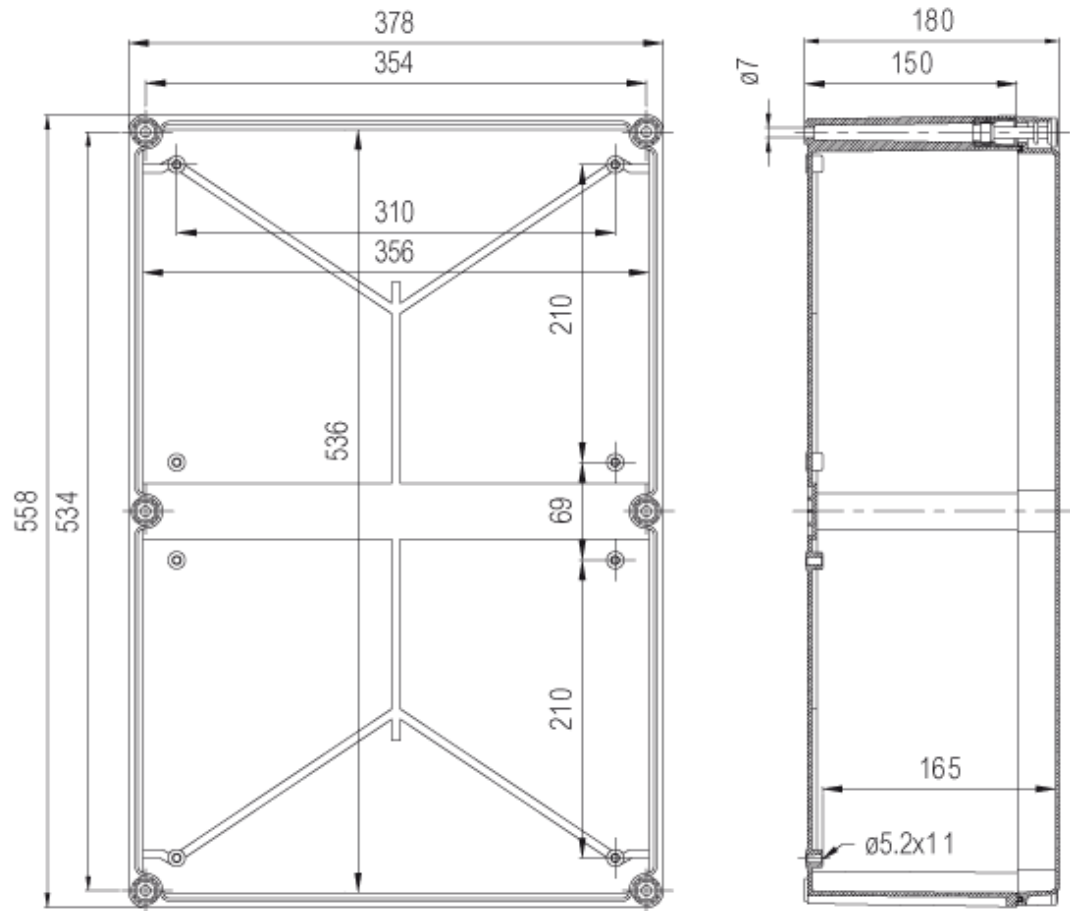

Dimensions :

mm :

Height

560

Width

380

Depth

180

Accessories :

EKUVT Mounting plate, for enclosures:

inch : 22.05 14.96 7.09

Materials :

Material : Polycarbonate
Base colour : RAL_7035
Cover colour : RAL 7035 -light grey
Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 80
Temperature °F (continuous) : -40 ... 175

(518 x 338 x 1)

EKV 32 DIN-35 Mounting rail, for enclosures:
(335 x 35 x 1)

EKUZR Extension frame, for enclosures:
(560 x 380 x 50)

Ratings :

Ingress protection (EN 60529): IP65;
Impact Resistance (EN 62262): IK08;
electrical_insulation : Totally insulated
Halogen free (DIN/VDE 0472, Part 815) : Yes
UV resistance : UL 746C
Flammability Rating : UL 94 V0
Glow Wire Test (IEC 695-2-1) °C : 960C

Certificates :

DSS_FI_41597_A1