

AB 050504

FIBOX
Enclosing innovations



Sample image

Order symbol : AB 050504

Product nr : 7083500

Description : Enclosure, ABS



Remarks : Grey cover

EAN : 6418074010612

El. number :

- Finland : 3423473
- Denmark : 8212003185
- Sweden : 7083500

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

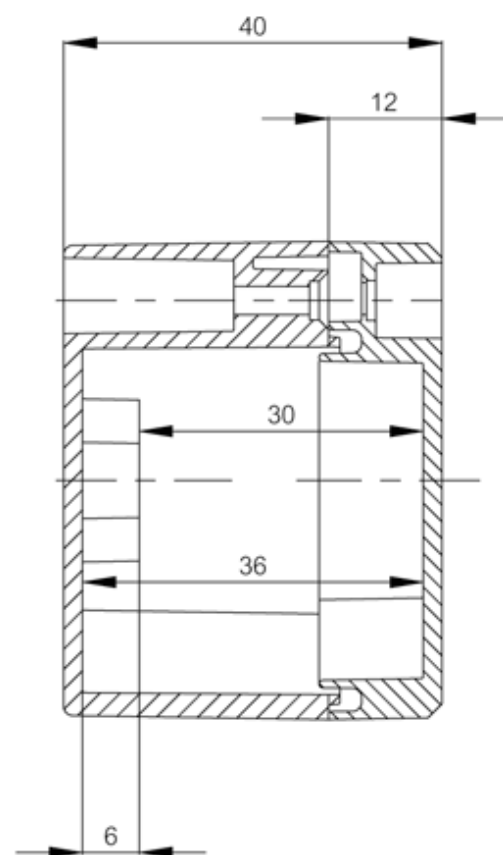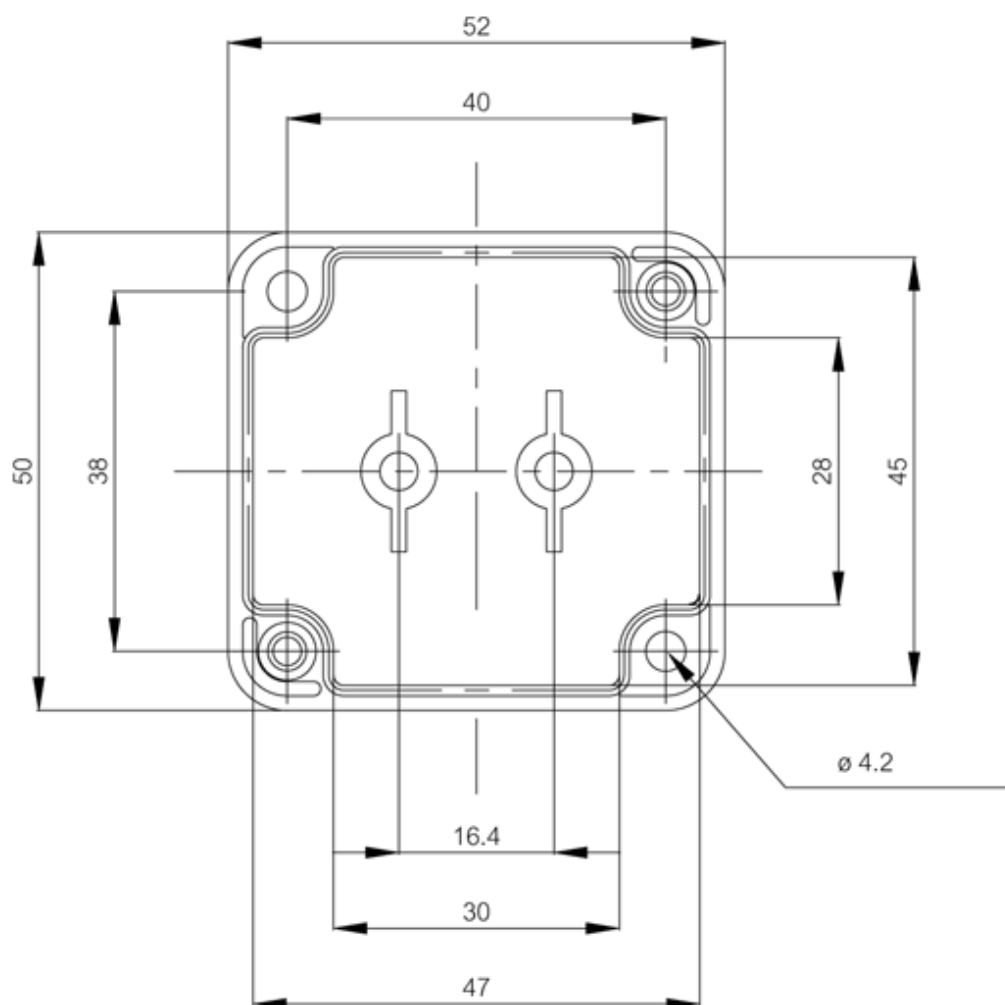

Dimensions :	Height	Width	Depth
mm :	52	50	40
inch :	2.05	1.97	1.57

Materials :	
Material :	ABS
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :	
Temperature °C (continuous) :	-40 ... 60
Temperature °F (continuous) :	-40 ... 140

Accessories :	
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 0505	Mounting plate, for enclosures: (26 x 48 x 1)
TH A	Grey plastic hinges (2 pcs)

Ratings :	
Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	-
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	650C

Certificates :	
SGSFimko_EURONORD	