


## PRODUCT NUMBER: 4609-0-07-15-00-00-03-0

### 4609-0-07-XX-00-00-03-0

Wire crimp termination. Accepts wire sizes 18 AWG Max. / 20 AWG Min.

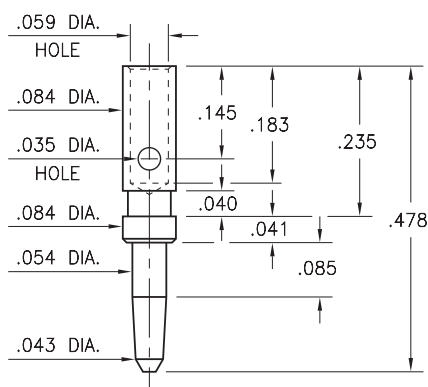

Standard Tolerances:  
Lengths:  $\pm .005$   
Diameters:  $\pm .002$   
Angles:  $\pm 2^\circ$

## DESCRIPTION

Crimp Terminal Pin

**Current Rating:**

Application Specific

**Operating Temperature Range:**

-55/+125° C (discontinuous)

**Mounting Feature:**

Wire Mount

**Wire Termination:**

Crimp 18-20 AWG

**Tail Type:** Solder tail

**Tail Diameter:** .054" (1,372mm)

**Packaging:** 07 - Packaged in Bulk

### Shell Plating

10  $\mu$ " Gold over Nickel

### Contact Plating

### ROHS



## ADDITIONAL NOTES & SPECIFICATIONS

In the interest of improved design, quality and performance, Mill-Max reserves the right to make changes in its specifications without prior notice. Specifications and tolerances are provided wherever possible. Due to the wide variety of interconnects Mill-Max offers, the specific tolerances vary from product to product. If you need information regarding the tolerance of a particular part, please contact Technical Services.

© 2020 Mill-Max Mfg. Corp.  
190 Pine Hollow Rd, Oyster Bay, NY 11771, USA  
Phone: 516.922.6000