


**PRODUCT NUMBER: 6061-0-00-15-00-00-03-0**

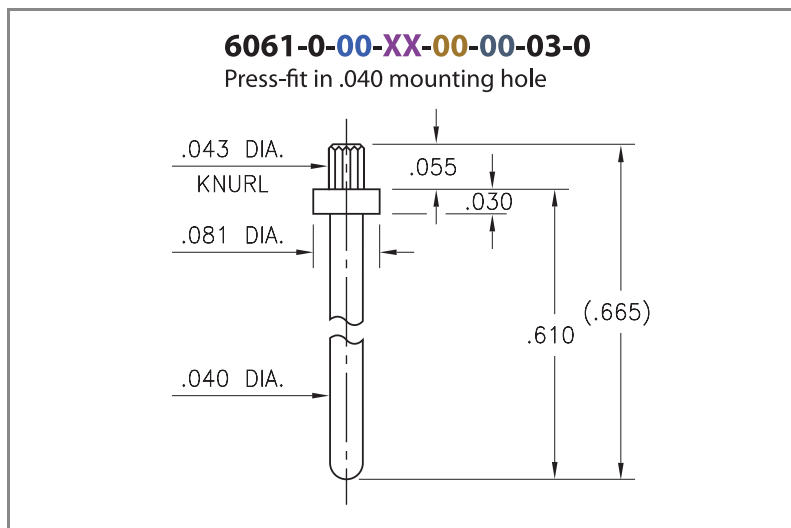

**DESCRIPTION**

Press-Fit PCB Pin

**Current Rating:**

Application Specific

**Operating Temperature Range:**

-55/+125° C (discontinuous)

**Mounting Feature:**

Press-Fit into a Non-Plated Through Hole (NPTH) or Insulator

**Tail Type:** Soldertail

**Mounting Hole:** .040" (1,016mm)

**Tail Diameter:** .040" (1,016mm)

**Packaging:** 00 - Packaged in Bulk

<b>Shell Plating</b>	<b>Contact Plating</b>	<b>ROHS</b>
----------------------	------------------------	-------------

10 μ" Gold over Nickel



**ADDITIONAL NOTES & SPECIFICATIONS**

In the interest of improved design, quality and performance, Mill-Max reserves the right to make changes in its specifications without prior notice. Specifications and tolerances are provided wherever possible. Due to the wide variety of interconnects Mill-Max offers, the specific tolerances vary from product to product. If you need information regarding the tolerance of a particular part, please contact Technical Services.

© 2020 Mill-Max Mfg. Corp.  
 190 Pine Hollow Rd , Oyster Bay, NY 11771, USA  
 Phone: 516.922.6000