


Quartz Crystal


SMD-version

part no.	12.86513
model	KX – 6T
frequency	25.0 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±30 ppm
temperature tolerance -40° ~ +85°C	±100 ppm
load capacitance C_L	16 pF
series resistance R1 max.	80 Ohm
aging at 25°C (first year) max.	±2 ppm
shunt capacitance C_O max.	3.5 pF
drive level max.	100 μ W
contents of reel	1000 pcs.


Dimensions (mm):

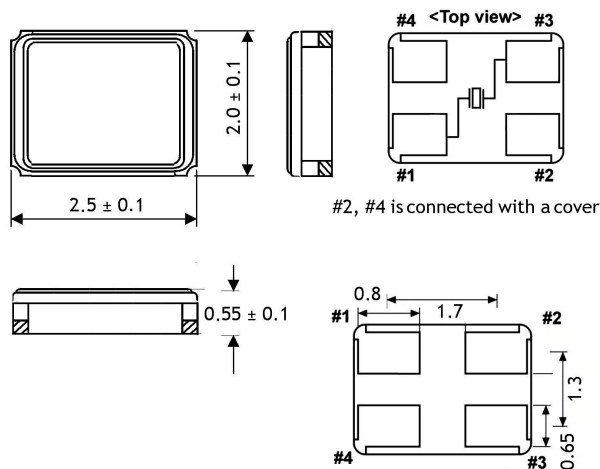


Reflow soldering condition:

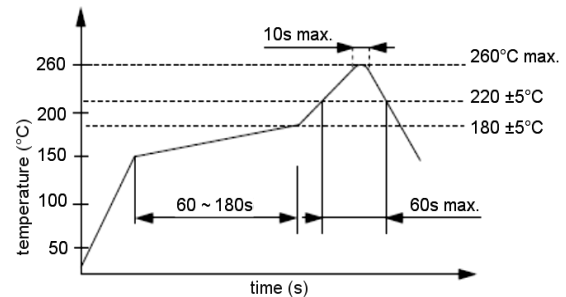

Suggested soldering pad:

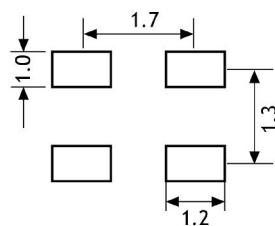

Tape specification:

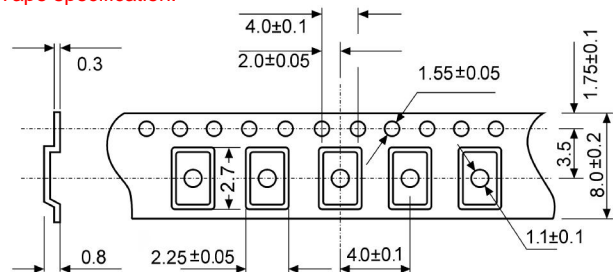

reel diameter 178 mm