


Quartz Crystal


SMD-version

model	KX - 7
frequency	26,0 MHz
mode	fundamental
operating temperature	-20° ~ +70°C
frequency tolerance at +25°C	± 30 ppm
temperature tolerance -20° ~ +70°C	± 30 ppm
load capacitance C_L	12 pF
series resonance R1 max.	60 Ohm
aging at +25°C (first year) max.	± 2 ppm
shunt capacitance C_0 max.	3,5 pF
drive level max.	100 µW
contents of reel	1000 pcs.
part no.	12.60003


Dimensions (mm):

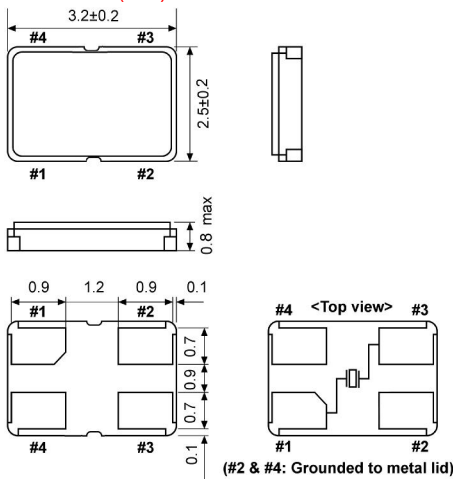

Reflow soldering condition:

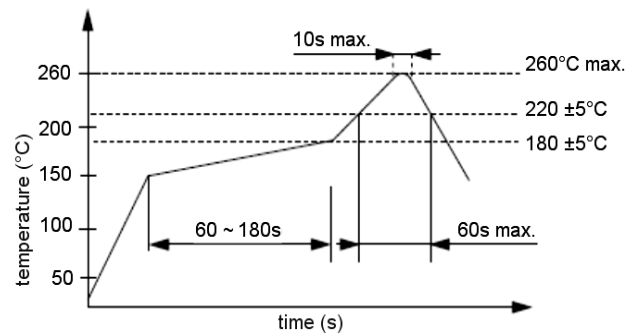

Suggested soldering pad:

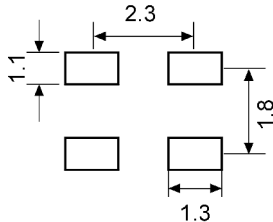

Tape specification:

