


Quartz Crystal


SMD-version

part no.	12.60007
model	KX – 7T
frequency	14.74560 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±30 ppm
temperature tolerance -40° ~ +85°C	±50 ppm
load capacitance C _L	16 pF
series resistance R ₁ max.	70 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance C ₀ max.	3.5 pF
drive level max.	200 µW
contents of reel	1000 pcs.


Dimensions (mm):

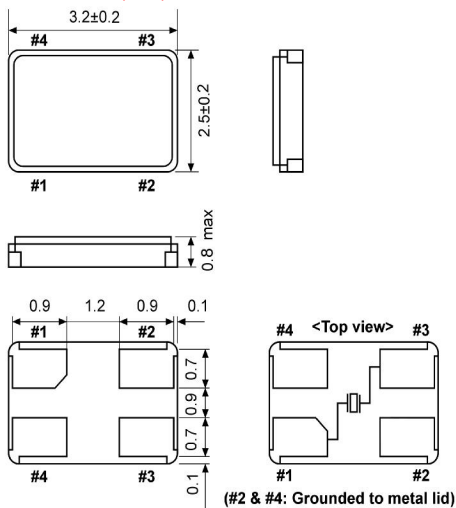

Reflow soldering condition:

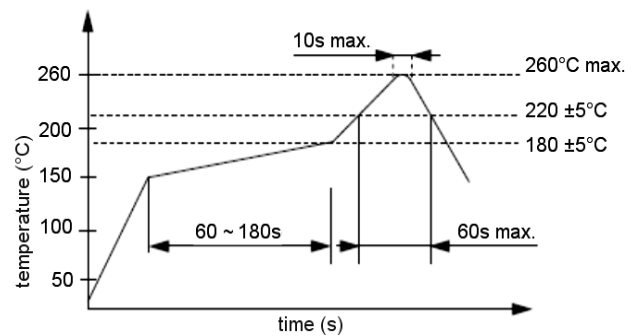

Suggested soldering pad:

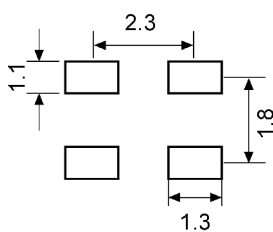

Tape specification:

