




Quartz Crystal


SMD-version

model	KX – 7T
frequency	32,0 MHz
mode	fundamental
operating temperature	40° ~ +85°C
frequency tolerance at +25°C	± 20 ppm
temperature tolerance -40° ~ +85°C	± 30 ppm
load capacitance C_L	12 pF
series resonance R1 max.	50 Ohm
aging at +25°C (first year) max.	± 2 ppm
shunt capacitance C_O max.	5,0 pF
drive level in μ W max.	100
contents of reel	1000 pcs.
part no.	12.60030


Dimensions (mm):

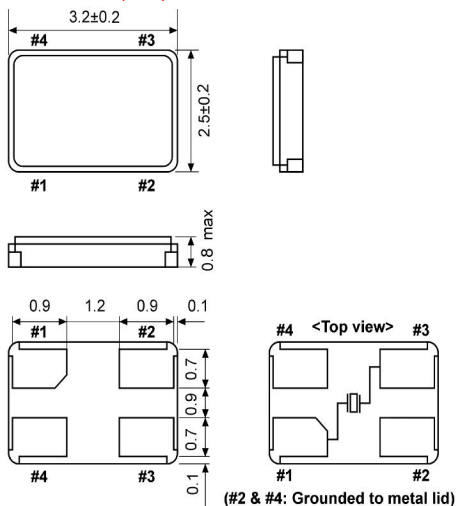

Reflow soldering condition:

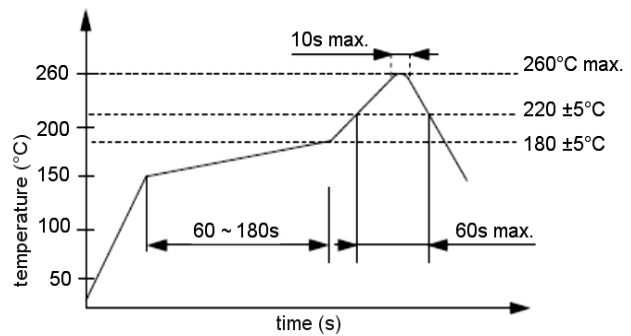

Suggested soldering pad:

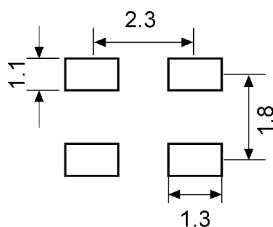

Tape specification:

