



# PUI audio



Data Sheet	AB2063B-2-LW50
------------	----------------


**Features:**

- Ultrathin and lightweight 20mm bender
- 6,300 Hz resonant frequency
- 50mm lead wires for easy installation

**Specifications**

Parameters	Values	Units
Resonant Frequency	$6,300 \pm 600$	Hz
Resonant Impedance (Max)	$\leq 350$	Ohms
Max Input Voltage	30	Vp-p
Capacitance (@ 120 Hz)	$10,000 \pm 30\%$	pF
Plate Material	Brass	-
Storage Temperature	-30 ~ 80	°C
Operating Temperature	-20 ~ 70	°C
Environmental Compliances	RoHS/REACH	Exempt. 7c-1

**Dimensions**

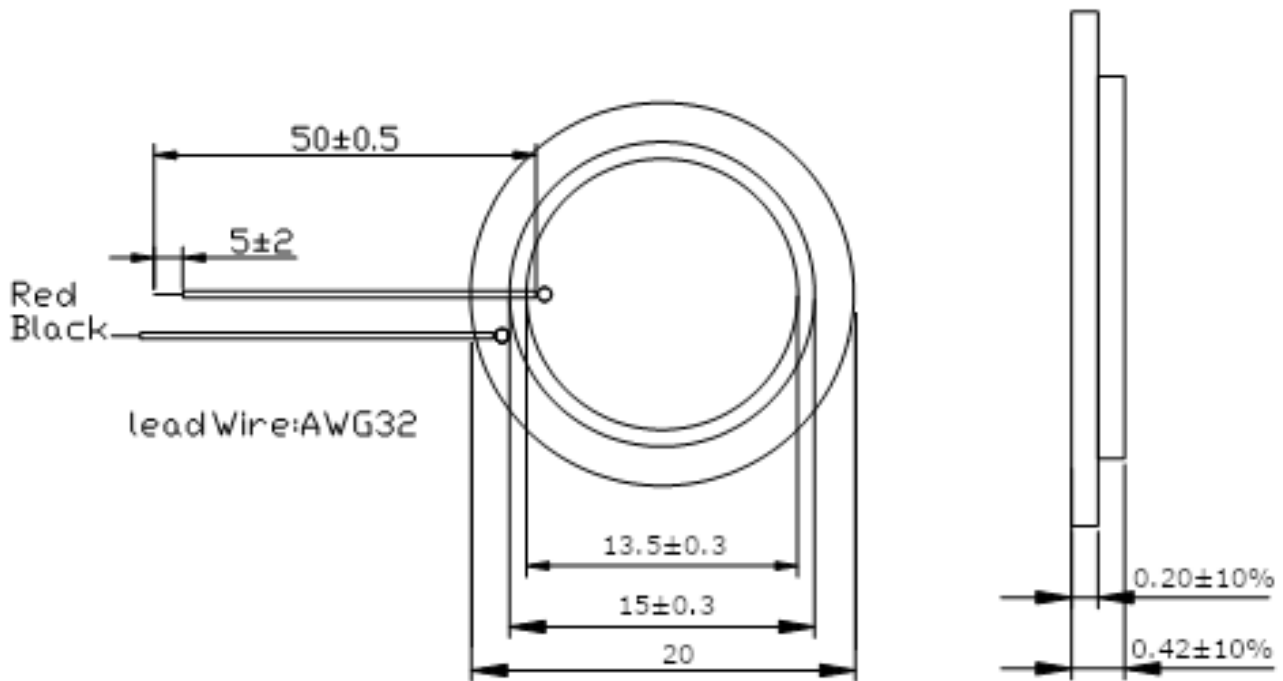

## Packaging

100pcs/bag, paper box packaging

### Specifications Revisions

Revision	Description	Date	Approved
A	Released from Engineering	3/6/2024	JD

Note:

- Unless otherwise specified:
  - All dimensions are in millimeters.
  - Default tolerances are  $\pm 0.5\text{mm}$  and angles are  $\pm 3^\circ$ .
- Specifications subject to change or withdrawal without notice.