


# HSK-MZ-E EMC - cable gland

With strain relief

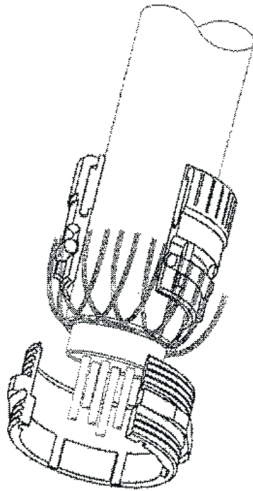

## HSK-MZ-E

EMC cable gland with double bracket strain relief.

### Application

- Plant and machine construction
- Automation technology
- Vehicle construction and shipbuilding
- Installation technology

### Material

Brass, nickel plated  
Clamp: Polyamide  
Seal: NBR  
O-ring: NBR


### Properties

- Easy to assemble
- Completely watertight
- Optimum strain relief
- Large clamping areas

### Technical data

Protection class: IP 68 - 10 bar / IP 69K

Temperature range: -40°C up to +100°C

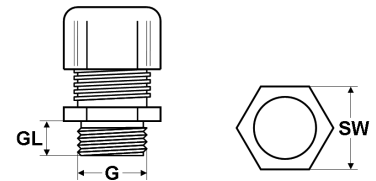

### Dimensions

G Thread size  
GL Thread length  
SW Spanner size

### Metric thread

Part no.	Size Metr.	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/ 100 items at a purchase of		
						up to 100	101 - 500	501 - 1000
98070	M12 x 1,5	3,0 - 6,5	6,5	14	50	o. r.	o. r.	o. r.
98071	M16 x 1,5	6,0 - 10,0	6,0	20	50	o. r.	o. r.	o. r.
98072	M20 x 1,5	10,0 - 14,0	6,0	24	50	o. r.	o. r.	o. r.
98073	M25 x 1,5	13,0 - 18,0	7,0	30	25	o. r.	o. r.	o. r.
98074	M32 x 1,5	18,0 - 25,0	8,0	40	25	o. r.	o. r.	o. r.
98075	M40 x 1,5	22,0 - 32,0	8,0	50	10	o. r.	o. r.	o. r.
90162	M50 x 1,5	32,0 - 38,0	9,0	57	5	o. r.	o. r.	o. r.
90163	M63 x 1,5	37,0 - 44,0	10,0	64 / 68	5	o. r.	o. r.	o. r.

### PG thread

Part no.	Size PG	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/ 100 items at a purchase of		
						up to 100	101 - 500	501 - 1000
98061	7	3,0 - 6,5	5,0	14	50	o. r.	o. r.	o. r.
98062	9	4,0 - 8,0	6,0	17	50	o. r.	o. r.	o. r.
98063	11	6,0 - 10,0	6,0	20	50	o. r.	o. r.	o. r.
98064	13,5	6,0 - 12,0	6,5	22	50	o. r.	o. r.	o. r.
98065	16	10,0 - 14,0	6,5	24	50	o. r.	o. r.	o. r.
98201	21	13,0 - 18,0	7,0	30	25	o. r.	o. r.	o. r.
98066	29	18,0 - 25,0	8,0	40	25	o. r.	o. r.	o. r.
98067	36	22,0 - 32,0	8,0	50	10	o. r.	o. r.	o. r.
98068	42	32,0 - 38,0	9,0	57	5	o. r.	o. r.	o. r.
98069	48	37,0 - 44,0	10,0	64	5	o. r.	o. r.	o. r.

### NPT thread

Part no.	Size NPT	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/ 100 items at a purchase of		
						up to 100	101 - 500	501 - 1000
92908	3/8"	4,0 - 8,0	15,0	17 / 19	50	o. r.	o. r.	o. r.
92909	1/2"	6,0 - 12,0	13,0	22 / 24	50	o. r.	o. r.	o. r.
92910	3/4"	13,0 - 18,0	13,0	30	25	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request