



Part Number : [191310111](#)


Product Description : InsulKrimp Block Spade Tongue Terminal for 10 to 12 AWG Wire, Stud Size 10 (M5), Length 27.31mm

Series Number : 19131

Status : Active

Product Category : Ring and Spade Terminals

Engineering Number : C-2105-10X BULK

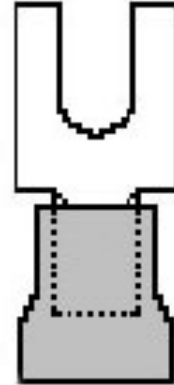

Documents & Resources

Drawings

[Drawing 191310111_sd.pdf](#)

Specifications

[Product Specification PS-19902-013-001.pdf](#)

[Product Specification PS-19902-009-001.pdf](#)

[Product Specification PS-19902-011-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19131
Description	InsulKrimp Block Spade Tongue Terminal for 10 to 12 AWG Wire, Stud Size 10 (M5), Length 27.31mm
Keyword	Spade Terminal, Spade Terminals
Product Family	Solderless Terminals
Product Name	InsulKrimp
Type	Spade Block
UPC	883906840211

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	1.789/g
Packaging Type	Bag
Stud Size	M10
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	6.40mm max.

Wire Size (AWG)	10, 12
Wire Size mm ²	3.30-5.00

This document was generated on Sep 05, 2023