



Mil. Spec. Phillips Rounded Head Screws

18-8 Stainless Steel, 0-80 Thread Size, 3/16" Long


91400A035



Thread Size	0-80
Length	3/16"
Threading	Fully Threaded
Head Diameter	0.116"
Head Height	0.044"
Drive Style	Phillips
Drive Size	No. 0
Material	Passivated 18-8 Stainless Steel
Hardness	Not Rated
Tensile Strength	80,000 psi
Screw Size Decimal Equivalent	0.060"
Thread Type	UNF
Thread Spacing	Fine
Thread Fit	Class 2A
Thread Direction	Right Hand
Head Type	Rounded
Rounded Head Style	Pan
Rounded Head Profile	Standard
System of Measurement	Inch
Specifications Met	Fed. Spec. FF-S-92, Fed. Spec. QQ-P-35, MS51958-121, NASM51958
RoHS	Not Compliant
REACH	REACH (EC 1907/2006) (06/25/2020, 209 SVHC) Compliant
Country of Origin	United States

Choose these pan head screws for their adherence to strict military standards for material and construction. Made from 18-8 stainless steel, they are chemical resistant and may be mildly magnetic. Length is measured from under the head.

Passivated screws meet Fed. Spec. QQ-P-35 for added protection against oxidation and corrosion.

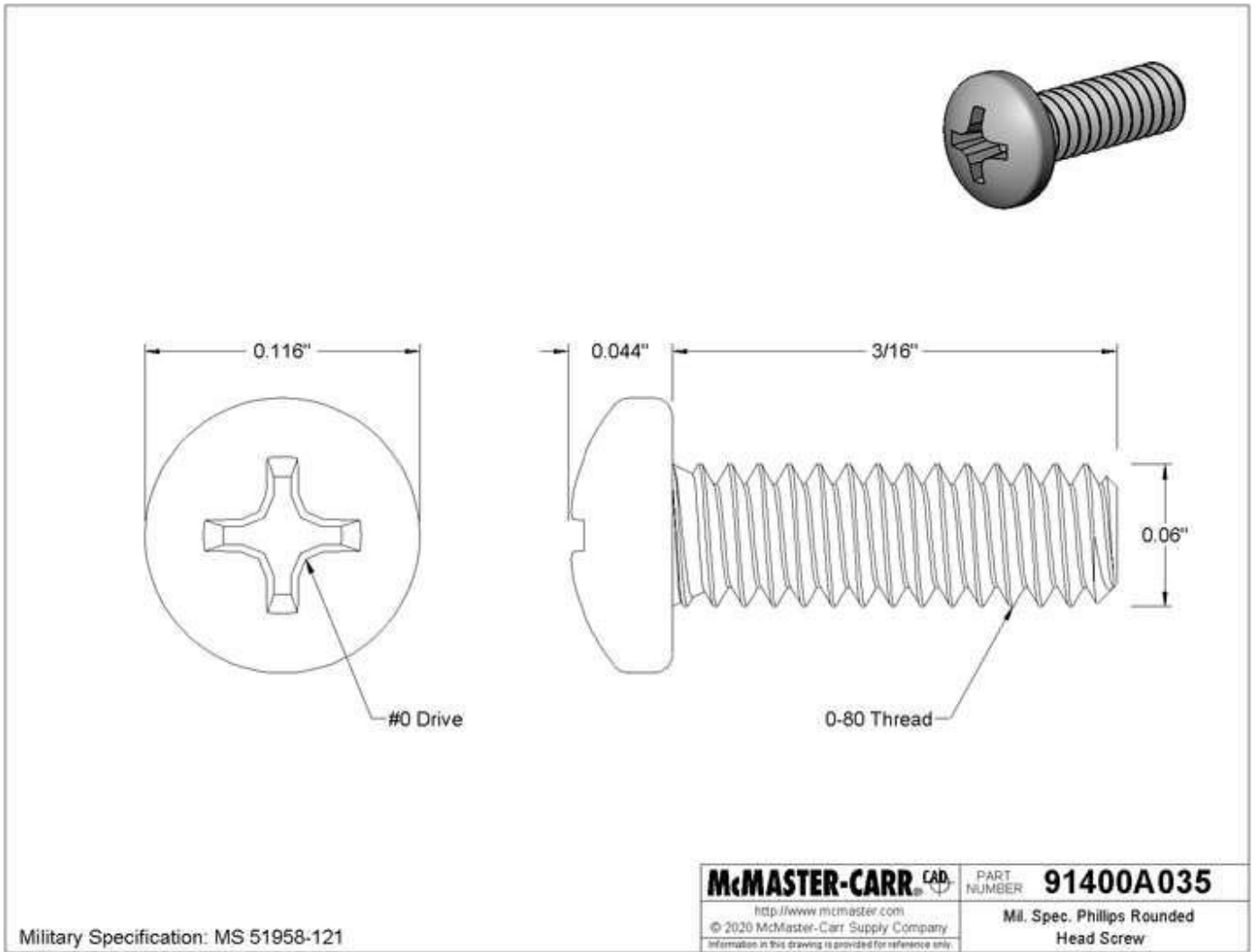

The information in this 3-D model is provided for reference only.