

Flat Cables AWG 28 Flat Ribbon Cable

Pitch 1.27 mm




SPECIFICATION:

Operating Voltage (Nom.): 300 V
 Operating Temperature: -20°C to 105°C
 Dielectric Strength: 2,000 Vac
 Operating Current (Max.): 480 mA at 300 V
 Version: UL certificated UL-Style 2651
 Note: flame retardant acc. to UL758






MATERIAL:

Material (Conductor): copper, tin plated
 Material (Sheath): PVC

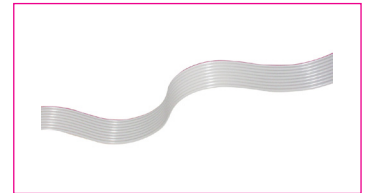

HANDLING:

Packaging: ring
 Packing Unit: 100 ft
 Note: other packaging on request

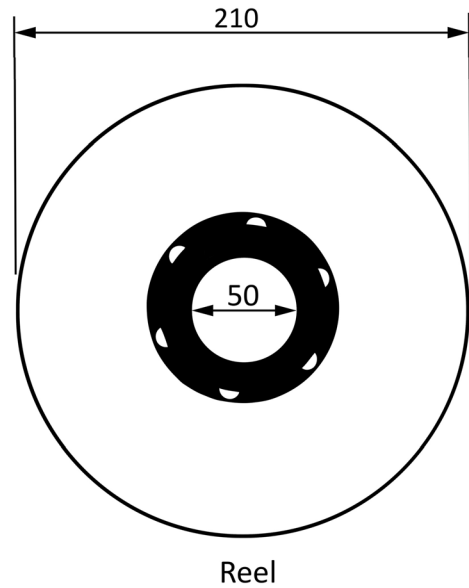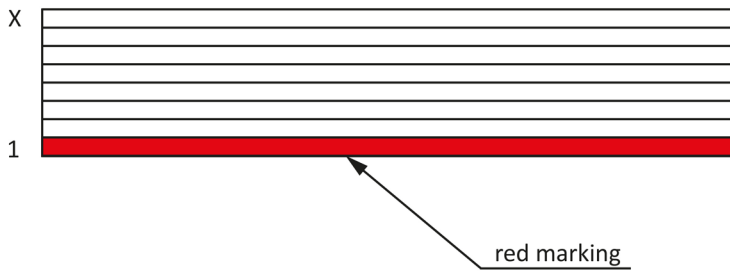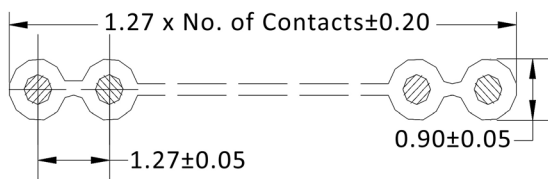

Order Information

Identifier:	No. of Contacts:	Colour:
28AWG	#	GR
Flat ribbon cable 28AWG	4: 4 poles	grey
	6: 6 poles	
	8: 8 poles	
	9: 9 poles	
	10: 10 poles	
	14: 14 poles	
	16: 16 poles	
	20: 20 poles	
	25: 25 poles	
	26: 26 poles	
	34: 34 poles	
	37: 37 poles	
	40: 40 poles	
	50: 50 poles	
	60: 60 poles	
	64: 64 poles	