

Flat Ribbon Cables AWG 28 Flat Ribbon Cable

Pitch 1.0 mm



SPECIFICATION:

Operating Voltage (Nom.): 300 V
 Operating Temperature: -20°C to 105°C
 Dielectric Strength: 2,000 Vac
 Version: UL certificated UL-Style 2651







MATERIAL:

Material (Conductor): copper, tin plated
 Material (Sheath): PVC

HANDLING:

Packaging: ring
 Packing Unit: 100 ft
 Note: other packaging on request

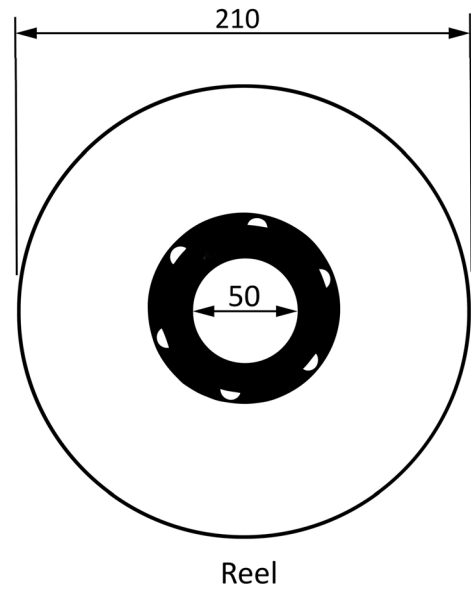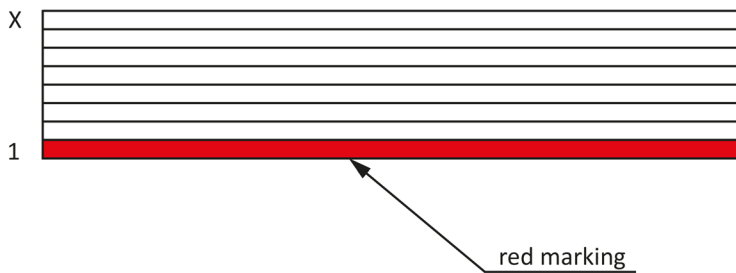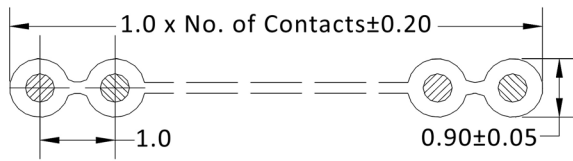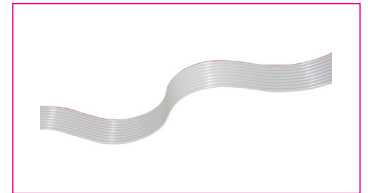

Order Information

Identifier:	No. of Contacts:	Pitch:	Colour:
28AWG	#	RM1	
Flat ribbon cable 28AWG	9: 9 poles	pitch 1.0 mm	grey
	10: 10 poles		
	14: 14 poles		
	16: 16 poles		
	20: 20 poles		
	25: 25 poles		
	26: 26 poles		
	34: 34 poles		
	40: 40 poles		
	44: 44 poles		
	50: 50 poles		