

SPECIFICATION:

Operating Current (Nom.):	1.5 A
Operating Temperature:	0°C to 70°C
Insulation Resistance (Min.):	500 MΩ
Contact Resistance (Max.):	40 mΩ
Dielectric Strength:	1,000 Vac

MATERIAL:




Material (Terminal):	phosphor bronze, nickel plated and gold plated
Material (Housing):	PBT
Flammability Class:	UL 94 V-0
Material (Shield):	brass, nickel plated
Material (Contact Area):	phosphor bronze, gold plated

HANDLING:



Processing:	wave soldering
Packaging:	tray
PU:	110 piece(s)

TOLERANCE:

.X:	± 0.38
.XX:	± 0.25

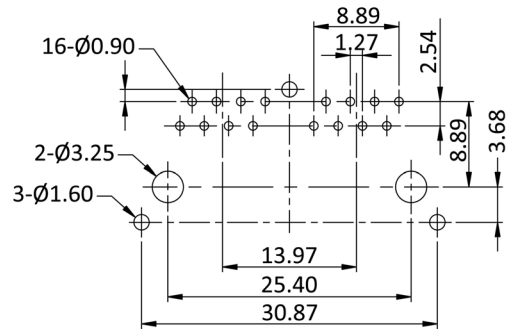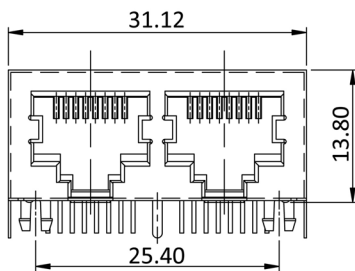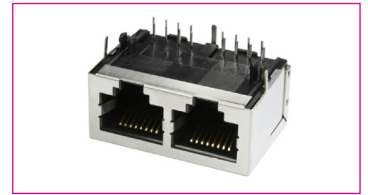

PCB Layout / Top View

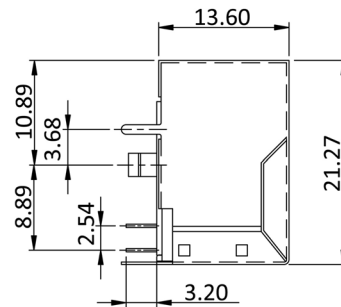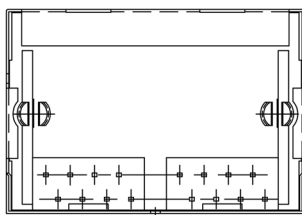

Order Information

Identifier:

3012S02

Contact Plating:

6 μ" gold *

Modular jack 2xRJ45 shielded, pcb mount