

**Female Header
Pitch 2.54 mm straight**

Double row, row space 7.62 mm



**RoHS
COMPLIANT**

SPECIFICATION:

Current rating: 3 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 550 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:






Housing: PBT UL94V-0
 Contacts: Copper alloy

HANDLING:

Processing: Wave soldering
 Packing: Tube

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

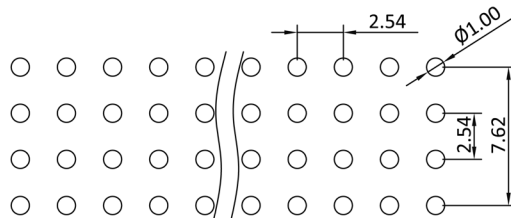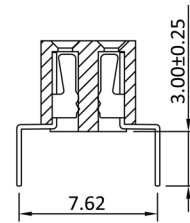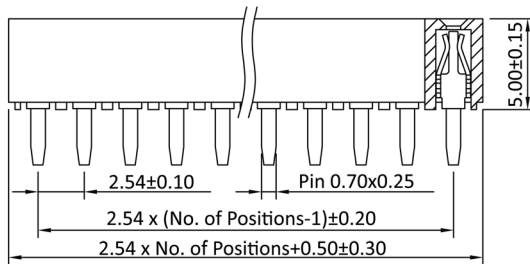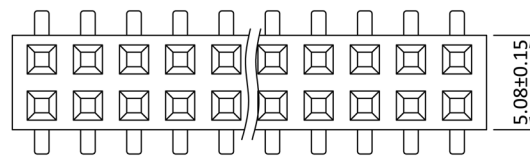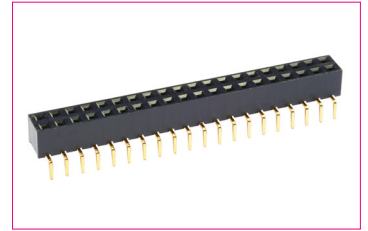

Recommended PCB Layout
(PCB Tolerance ±0.05)

Order-Information

| Identifier: | No. of contacts: | Contact Plating: |
|---|---|---------------------------------|
| BC | # | # |
| Female Header Pitch 2.54 mm double row straight Row Space 7.62 mm | 4: 2 x 2 6: 2 x 3 8: 2 x 4 : 80: 2 x 40 | G: Gold Flash * S: Selective |

* = standard