

Female Headers
Pitch 2.54 mm, angled

Single row, height 8.5 mm



SPECIFICATION:

Operating Current (Nom.): 3 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:

 




Material (Housing): PBT
 Flammability Class: UL 94 V-0
 Material (Contact Area): copper alloy, gold plated

HANDLING:

Processing: wave soldering
 Packaging: tray

TOLERANCE:

.X: ± 0.25
 .XX: ± 0.20

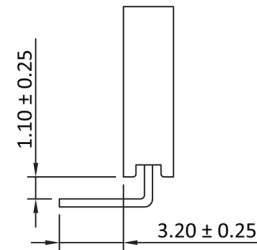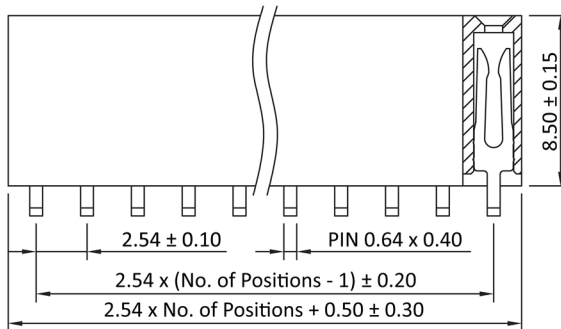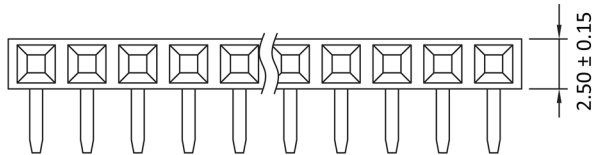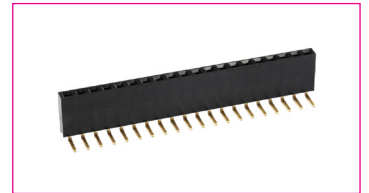

Recommended PCB Layout
(PCB TOLERANCE ± 0.05)

Order Information

Identifier:

BL

Female header pitch 2.54 mm single row angled

Version:

W

angled

No. of Contacts:

#

- 1X2: 1 x 2
- 1X3: 1 x 3
- 1X4: 1 x 4
- :
- 1X40: 1 x 40