

# D-Sub Connectors High Density, PCB Mounting, angled

## Female Connectors with Threaded Bolt UNC 4/40



### SPECIFICATION:

Operating Current (Nom.):	3 A
Operating Temperature:	-55°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	13 mΩ
Dielectric Strength:	500 Vac

### MATERIAL:




Material (Terminal):	copper alloy, tin plated
Material (Housing):	steel, nickel plated
Flammability Class:	UL 94 V-0
Material (Insulation):	PBT
Material (Contact Area):	copper alloy, gold plated

### HANDLING:



Processing:	wave soldering
Packaging:	tray

### TOLERANCE:

.X:	± 0.25
.XX:	± 0.20

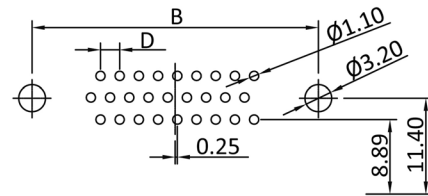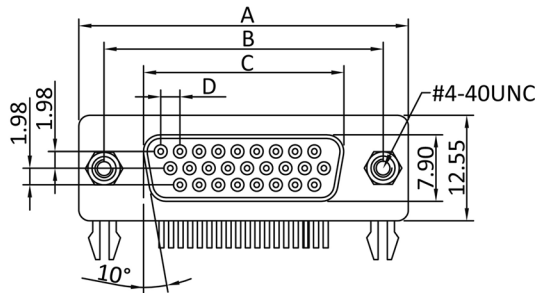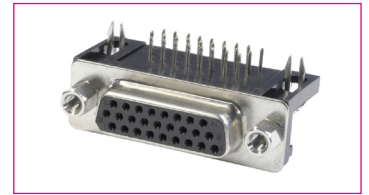

Recommended PCB Layout  
(PCB Tolerance ±0.05)

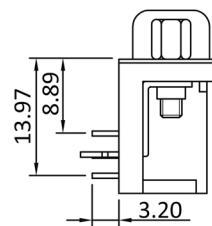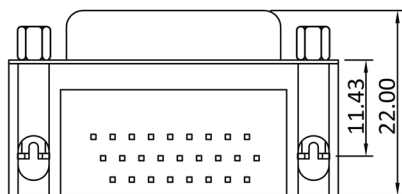

### Dimensions

Number of Contacts:	A:	B:	C:
15	30.81	24.99	16.33
26	39.14	33.32	24.66
44	53.04	47.04	38.38

### Order Information

Identifier:	No. of Contacts:	Version:
BU	#	HDW
D-Sub High Density Female with solder pins	15: 15 poles	High Density angled
	26: 26 poles	
	44: 44 poles	