


Quartz Crystal


SMD-version

model	KX - 7
frequency	14,74560 MHz
mode	fundamental
operating temperature	-20° ~ +70°C
frequency tolerance at +25°C	± 30 ppm
temperature tolerance -20° ~ +70°C	± 50 ppm
load capacitance C_L	12 pF
series resonance R1 max.	70 Ohm
aging at 25°C (first year) max	± 2 ppm
shunt capacitance C_0 max.	3,5 pF
drive level max.	0,05 mW
contents of reel	1000 pcs.
part no.	12.88657


Dimensions (mm):

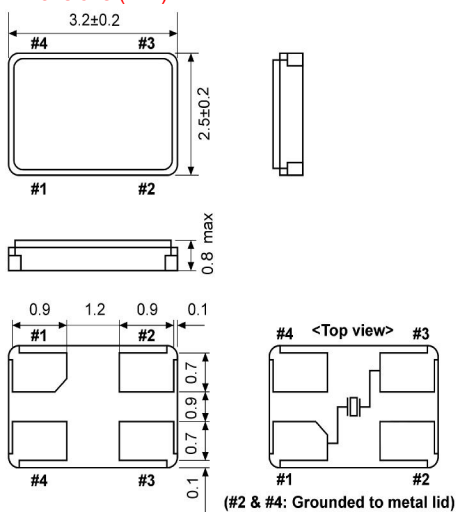

Reflow soldering condition:

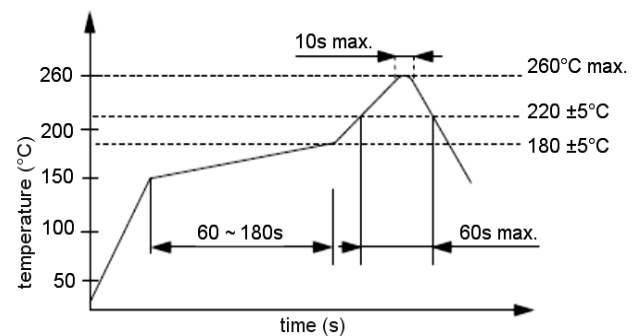

Suggested soldering pad:

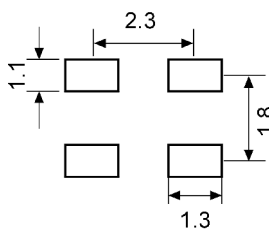

Tape specification:

