


**SPECIFICATION:**

Operating Temperature: -35°C to 85°C  
 Extraction Force: ≤ 80 N  
 Moisture Content: 1%~3%  
 Surface Roughness: level 3.2  
 Tolerance of Tooth Spacing: ≤ 0.1 mm

**MATERIAL:**

Material: polyamide 66 (PA)  
 Flammability Class: UL 94 V-2

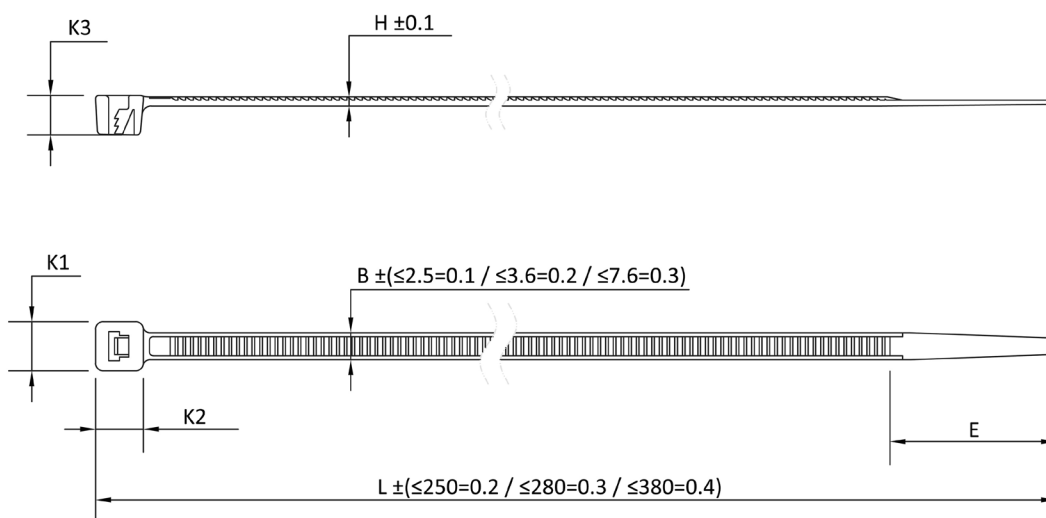

**Dimensions**

Version:	L (mm):	B (mm):	H (mm):	E (mm):	K1 (mm):	K2 (mm):	K3 (mm):
8025	80	2.5	0.95	19	4.5	4.5	4
10025	100	2.5	0.95	19	4.5	4.5	4
15025	150	2.5	1.05	19	4.5	4.5	4
20025	200	2.5	1.05	19	4.5	4.5	4
14036	140	3.6	1.15	22.5	6.4	6.2	5.15
20036	200	3.6	1.2	22.5	6.4	6.2	5.15
37036	370	3.6	1.27	22.5	6.4	6.2	5.15
18046	180	4.6	1.2	24.5	7.8	7	5.8
28048	280	4.8	1.4	24.5	8.1	7.3	6.15
38048	380	4.8	1.45	26.5	8.1	7.3	6.15
37076	370	8.6	1.6	28.5	12.8	10	7.95

**Order Information**

Identifier:	Version:	Colour:
<b>ECK</b>	<b>#</b>	<b>#</b>
Cable tie	8025: 80 x 2.5 mm (only natural)	empty: natural
	10025: 100 x 2.5 mm (all colours)	B: black
	15025: 150 x 2.5 mm (only natural)	R: red
	20025: 200 x 2.5 mm (all colours)	BL: blue
	14036: 140 x 3.6 mm (only natural)	G: green
	20036: 200 x 3.6 mm (only natural)	Y: yellow
	37036: 370 x 3.6 mm (only natural)	
	18046: 180 x 4.6 mm (only natural)	
	28048: 280 x 4.8 mm (only natural)	
	38048: 380 x 4.8 mm (only natural)	
	37076: 370 x 7.6 mm (only natural & black)	