

Mounting Accessories Spacer Bolts Metal

Brass, Inner / Outer Thread M3 AF 5.0



MATERIAL:


Material: copper alloy brass, nickel plated

HANDLING:

Packaging: bulk

TOLERANCE:

.X: ± 0.38
.XX: ± 0.25

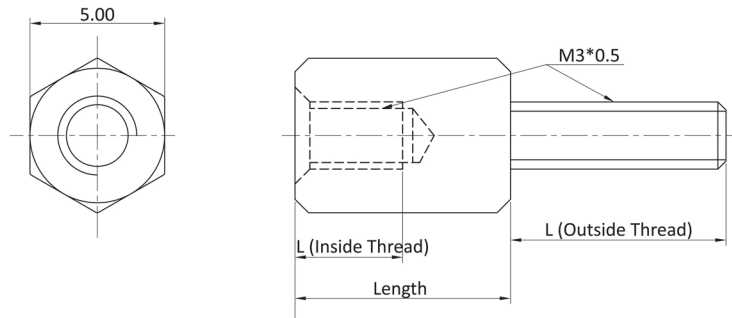

Dimensions

Length (mm):	L (mm) (Inside Thread):	L (mm) (Outside Thread):
5	2.5	8
6	3	8
8	4	8
10	5	8
11	5.5	8
12	6	8
15	10	8
18	10	8
20	10	8
25	10	10
30	10	10
35	10	10
40	10	10
45	10	10
50	10	10

Order Information

Identifier:	Thread:	Length:	Version:	Width across flats:	Material:	Packing Unit:
D	3X	#	A	5	M	#
Spacer bolt	M3	05: 5 mm 06: 6 mm 08: 8 mm 10: 10 mm 11: 11 mm 12: 12 mm 15: 15 mm 18: 18 mm 20: 20 mm 25: 25 mm 30: 30 mm 35: 35 mm (only H PU) 40: 40 mm (only H PU) 45: 45 mm (only H PU) 50: 50 mm (only H PU)	inner / outer thread	5 AF	brass, nickel plated	H: 100 pieces T: 1000 pieces