

Patch Cables Cat.6a extra slim

PiMF U/FTP



SPECIFICATION:

Frequency: 500 MHz
 Operating Temperature: -10°C to 60°C




MATERIAL:

Material (Sheath): LSZH
 Material (Shield): copper alloy, nickel plated
 Material (Contact Area): copper alloy, 3 µ" gold plating
 Cable Diameter (Max.): 3.8 mm
 Bending radius (Min.): 30 mm



HANDLING:

Packaging: Bag, single-packed

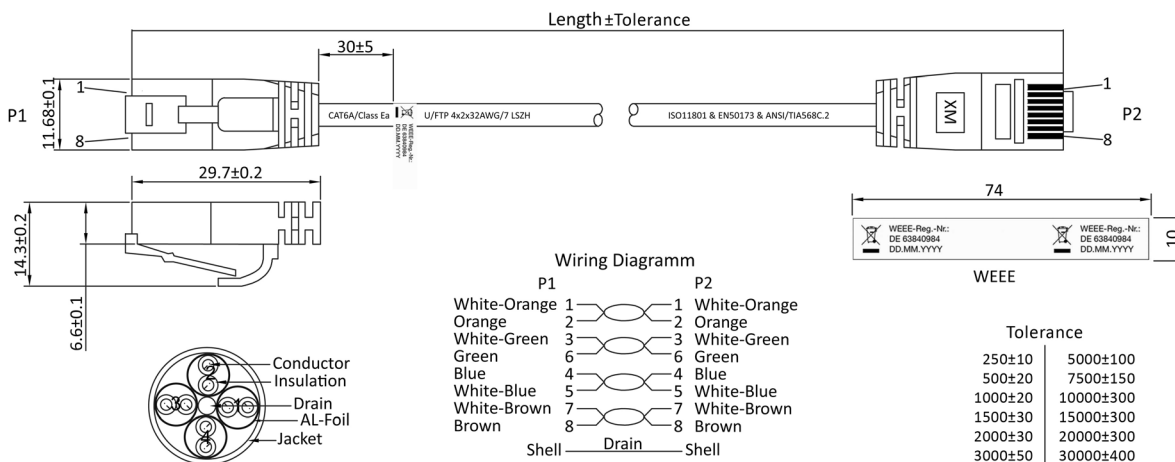

Order Information

Identifier:	Version:	Length:	Colour:
F6ATP	S	#	#
Patch Cord U/FTP Cat.6a shielded	extra slim	0,25: 0.25 m	GR: grey
		0,5: 0.5 m	SW: black
		1: 1.0 m	RT: red
		1,5: 1.5 m	BL: blue
		2: 2.0 m	GE: yellow
		3: 3.0 m	GN: green
		5: 5.0 m	
		7,5: 7.5 m	
		10: 10.0 m	
		15: 15.0 m	
		20: 20.0 m	
		30: 30.0 m	