

13.3" INDUSTRIAL-GARDE TOUCH SCREEN MONITOR



1920×1080



Touch Screen



VESA Mount




HDMI / DP / VGA



Model No.

FA1330/C | **FA1330/T**
Without touch | With touch

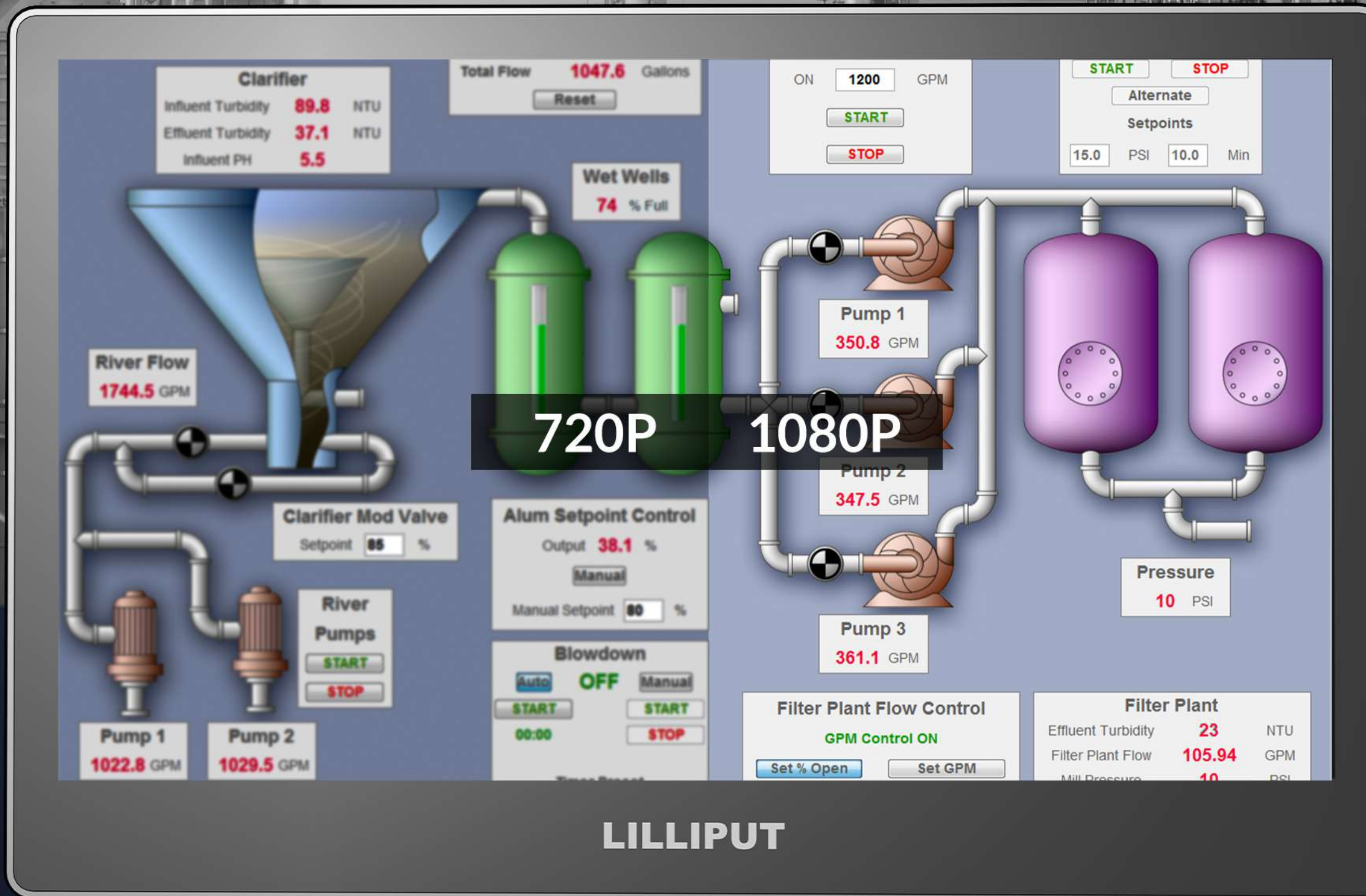

Adopt industrial-grade screen panel with excellent stability. Also, it features 13.3 inch 16:9 LCD panel with 1920×1080 physical resolution,



13.3" 1920×1080

13.3" Industrial-grade touch screen panel with 1920×1080 resolution.




FULL LAMINATION

Make with full lamination technology, which gives the screen better light transmission.

10-POINT CAPACITIVE TOUCH

HIGH QUALITY SENSITIVITY

The optional industrial-grade touch screen supports 10-point capacitive touch and thin-glove touch. Also, it will not be affected even when exposed to small amount of water droplets.

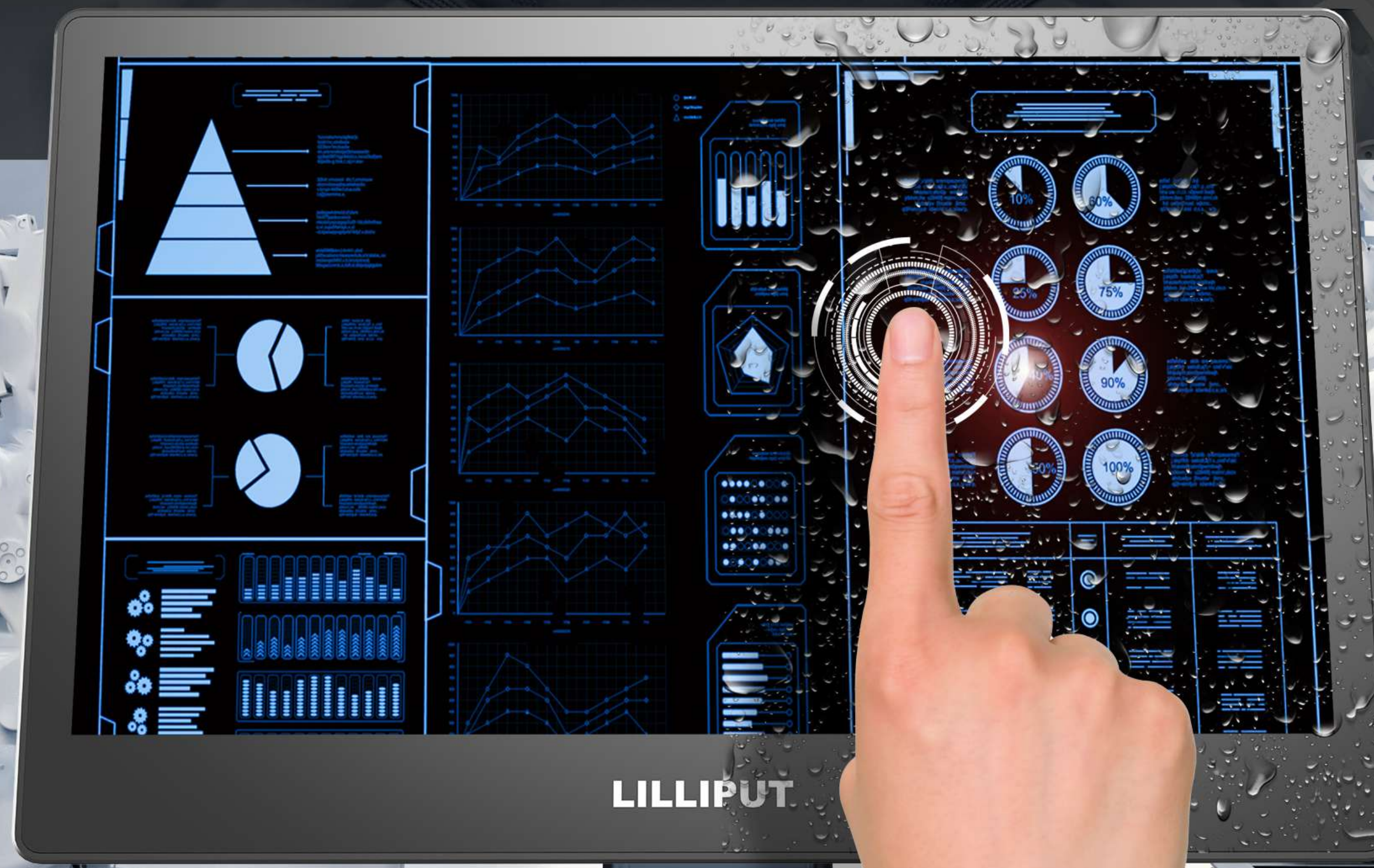

INTERFACES OF MONITOR

HDMI / VGA / DP INTERFACES

Equipped with three different video signal interfaces to meet different types of equipment. In addition to the monitor's built-in speakers, people can also listen to audio through earphone.



DP INPUT
Support up to 4K
60Hz video signal.


DC POWER IN
7V-24V Input.

VGA IN
Support up to 1080p 60Hz.

HDMI IN
Support up to 4K 30Hz.

USB
For touch function.

EARPHONE
Audio output with 3.5mm port.

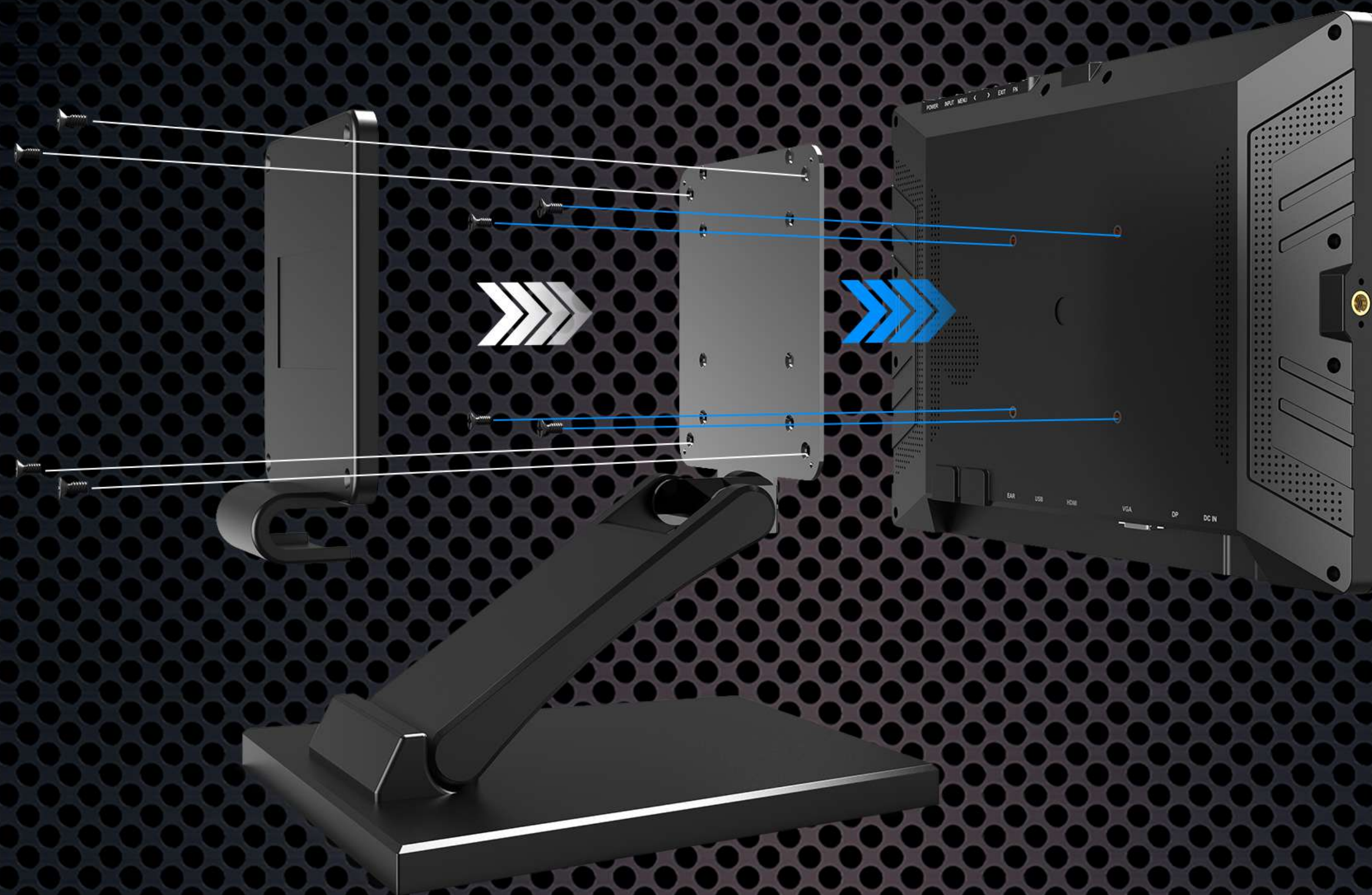

VESA 75MM BRACKET

FOLDABLE DESKTOP STAND (OPTIONAL)

With universal VESA 75mm compatible mounting, people can try different mounting brackets for different usage environments. Also, there are 1/4" mounting screw ports on both sides of the body, providing more options for integrated solutions.




APPLICATIONS

Industrial-grade touch monitor for a wide range of HMI applications.

SPECIFICATION

DISPLAY	Touch Screen	10-point capacitive touch
	Panel	13.3" LCD
	Physical Resolution	1920×1080
	Aspect Ratio	16:9
	Brightness	300 nits
	Contrast	800:1
	Viewing Angle	170°/ 170°(H/V)
INPUT	HDMI	1
	DP	1
	VGA	1
	USB	1 (For touch)
SUPPORTED FORMATS	HDMI	2160p 24/25/30, 1080p 24/25/30/50/60, 1080i 50/60, 720p 50/60...
	DP	2160p 24/25/30/50/60, 1080p 24/25/30/50/60, 1080i 50/60, 720p 50/60...
	VGA	1080p 24/25/30/50/60, 1080pSF 24/25/30, 1080i 50/60, 720p 50/60...
AUDIO IN/OUT	Speaker	2
	Ear Jack	3.5mm - 2ch 48kHz 24-bit
POWER	Input Voltage	DC 7-24V
	Power Consumption	≤12W (12V)
ENVIRONMENT	Operating Temperature	0°C~50°C
	Storage Temperature	-20°C~60°C
DIMENSION	Dimension(LWD)	320mm × 208mm × 26.5mm
	Weight	1.15kg

Note: Due to constant effort to improve products and product features, specifications may change without notice.

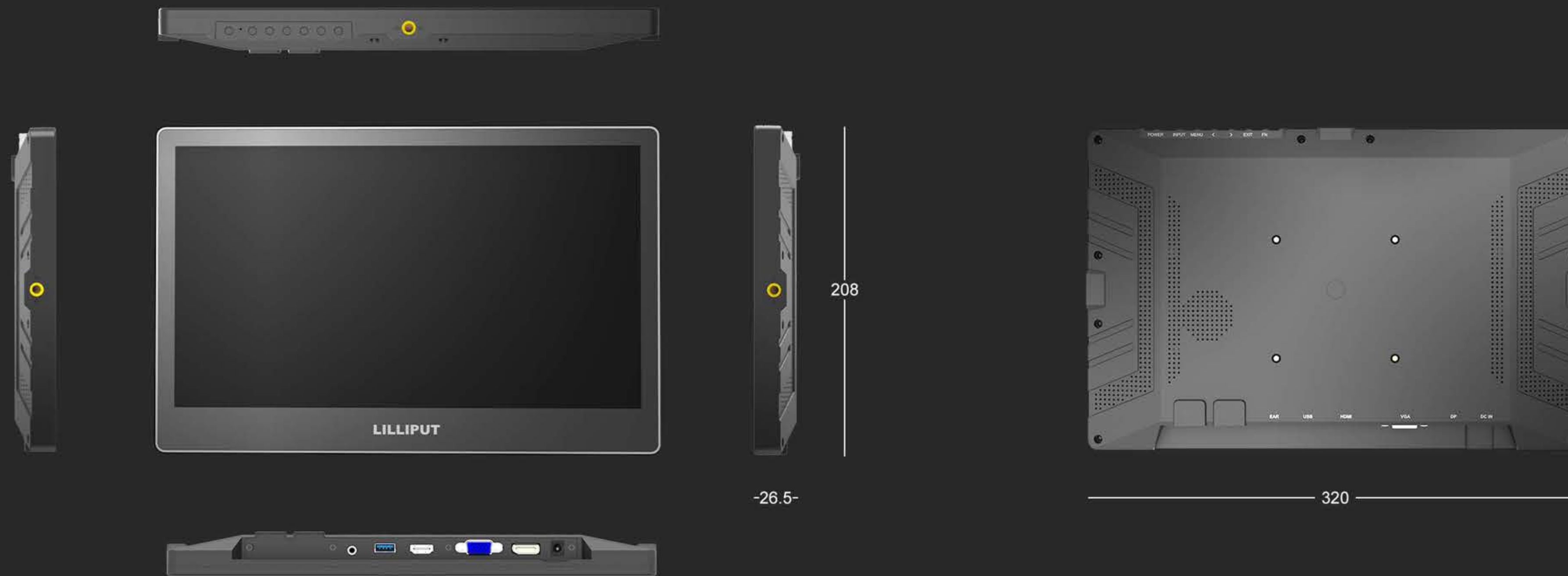

ACCESSORIES

STANDARD



12V 2A DC Power Adapter



1.5M HDMI A-A Cable




1.5M USB A-A Cable



E-User Manual

OPTIONAL

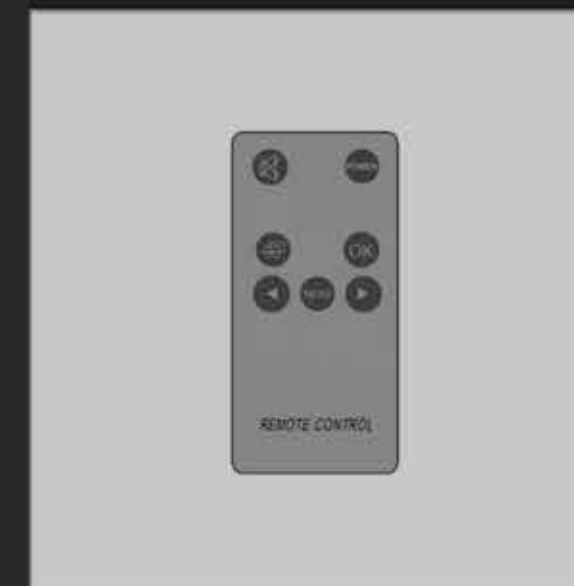

Remote Control



VESA 75mm Bracket