

SPECIFICATION:

Operating Current (Nom.): 1.5 A
 Operating Temperature: -40°C to 70°C
 Insulation Resistance (Min.): 500 MΩ
 Contact Resistance (Max.): 30 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:


Material (Terminal): phosphor bronze, nickel plated and tin plated
 Material (Housing): PBT
 Flammability Class: UL 94 V-0
 Material (Contact Area): phosphor bronze, gold plated

HANDLING:

Processing: wave soldering
 Packaging: tray

TOLERANCE:





.X: ± 0.25
 .XX: ± 0.20

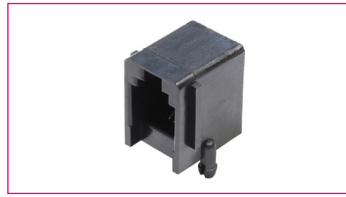

MJUSExxx



 MJUNxxx

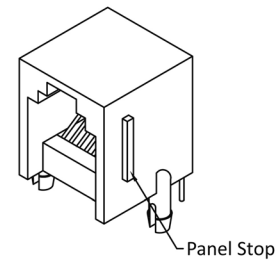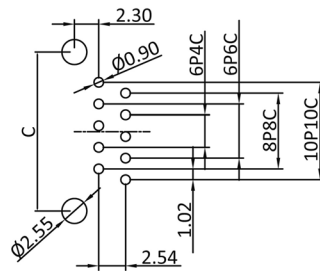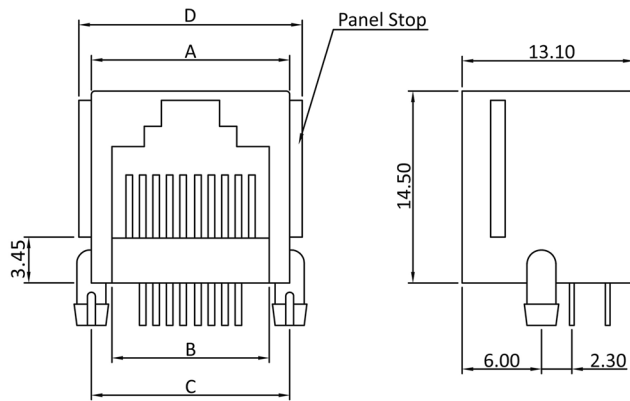

Dimensions

Number of Contacts:	A:	B:	C:	D:
4 w/o flange	10	7.85	10	-
6 w/o flange	12.2	9.9	12	-
8 w/o flange	15	11.85	15	-
4	10	7.85	10	12
6	12.2	9.9	12	14.2
8	15	11.85	15	16.9

Order Information

Identifier:	Flange:	No. of Contacts:	Conductors:	Contact Plating:	Colour:
MJUS	#	#	#	GA	B
Modular jack unshielded, pcb mount	N: w/o flange E: mit flange	4: 4P 6: 6P 8: 8P	4: 4C 6: 6C 8: 8C	6 µ" gold	black