

SPECIFICATION:



Operating Current (Nom.):	1.5 A
Operating Temperature:	-40°C to 125°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	1,000 Vac

MATERIAL:


Material (Terminal):	phosphor bronze, 3 μ" gold plating
Material (Housing):	polycarbonate
Flammability Class:	UL 94 V-2
Material (Contact Area):	phosphor bronze, 3 μ" gold plating

HANDLING:




Packaging:	bulk
------------	------

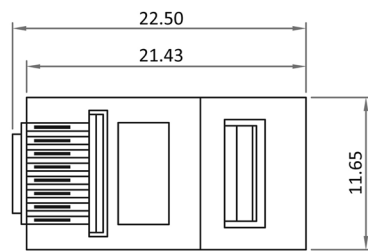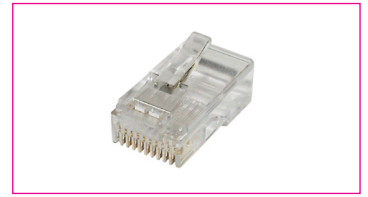

Flat Cable

 

Round Cable

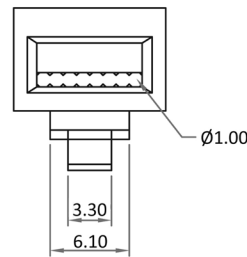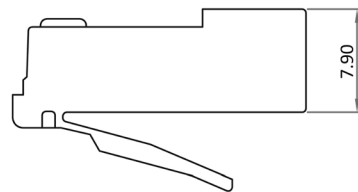 

Order Information

Identifier:
MPL10/10

Modular plug 10P10C unshielded

Version:
#

empty: for flat cable *
R: for round cable