

SPECIFICATION:



Operating Current (Nom.): 1.5 A
 Operating Temperature: -40°C to 70°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 1,000 Vac

MATERIAL:

Material (Terminal): phosphor bronze, gold plated
 Material (Housing): polycarbonate
 Flammability Class: UL 94 V-2
 Material (Contact Area): phosphor bronze, gold plated

HANDLING:

Packaging: bulk

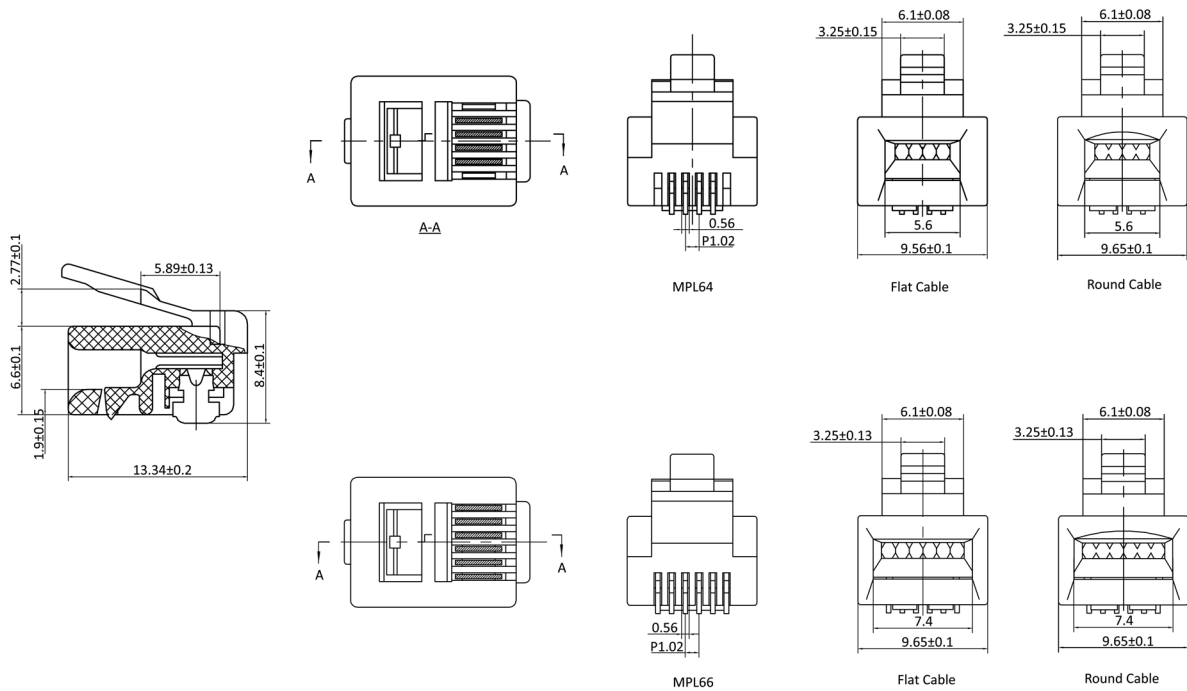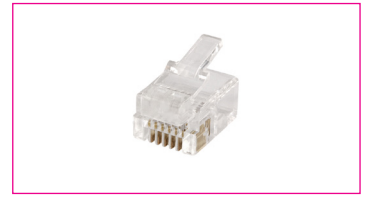

Order Information

Identifier:	Conductors:	Version:
MPL6	#	#
Modular plug 6P unshielded	4: 4C 6: 6C	empty: for flat cable R: for round cable