

SPECIFICATION:



Operating Current (Nom.):	1.5 A
Operating Temperature:	-40°C to 70°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	20 mΩ
Dielectric Strength:	1,000 Vac

MATERIAL:

Material (Terminal):	phosphor bronze, 3 μ" gold plating
Material (Housing):	polycarbonate
Flammability Class:	UL 94 V-0
Material (Contact Area):	phosphor bronze, 3 μ" gold plating

HANDLING:

Packaging:	bulk
------------	------

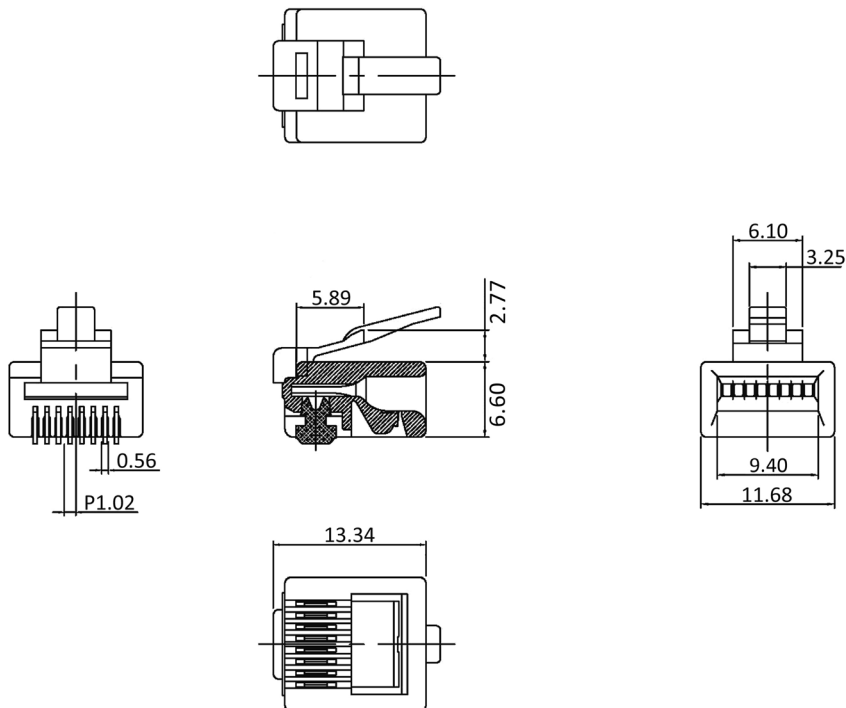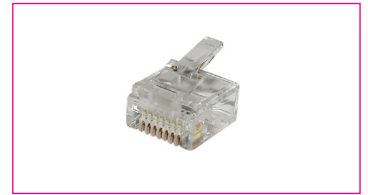

Order Information

Identifier:

MPL8/8K

Version:

for flat cable

Modular plug 8P8C short version unshielded