


SPECIFICATION:

Operating Voltage (Max.):	30 V
Operating Current (Nom.):	1.5 A
Operating Temperature:	-25°C to 80°C
Insulation Resistance (Min.):	100 MΩ
Contact Resistance (Max.):	50 mΩ
Dielectric Strength:	100 Vac
Insertion Force (Max.):	35 N
Extraction Force:	7 N

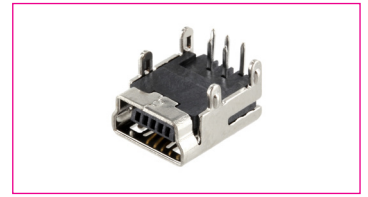

MATERIAL:


Material (Terminal):	copper alloy, tin plated
Material (Housing):	brass, nickel plated
Flammability Class:	UL 94 V-0
Material (Insulation):	thermoplastic
Material (Contact Area):	copper alloy, gold plated

HANDLING:

Packaging:	tray
------------	------

TOLERANCE:

.X:	± 0.30
.XX:	± 0.20

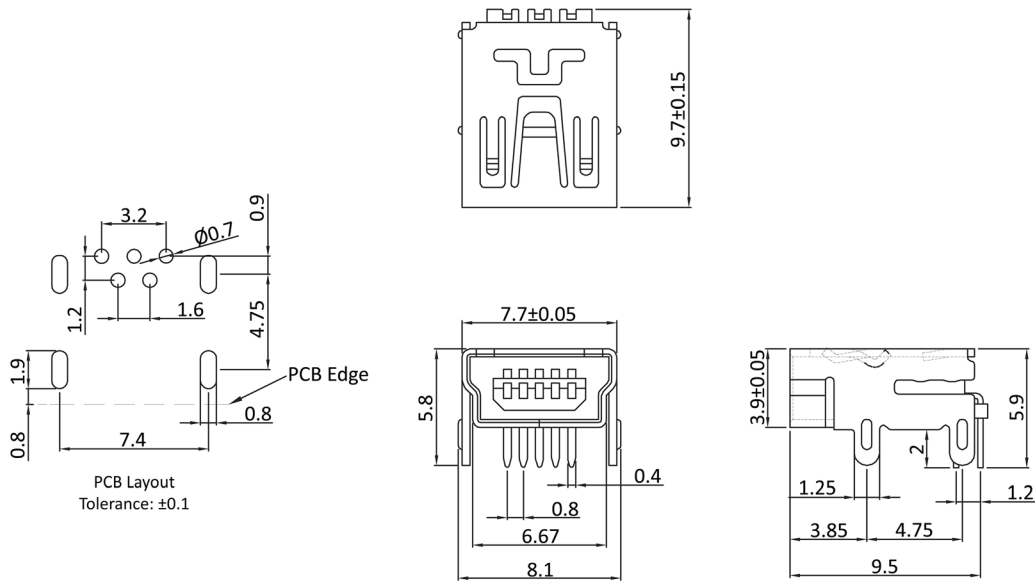

Order Information

Identifier:

MUB1B5W

Socket 5 poles angled