


**SPECIFICATION:**

Operating Voltage (Max.):	30 V
Operating Current (Nom.):	1 A
Operating Temperature:	-55°C to 105°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	500 Vac
Insertion Force (Max.):	30 N
Extraction Force:	4.9 N

**T & R**  
tape and reel

**SMT**

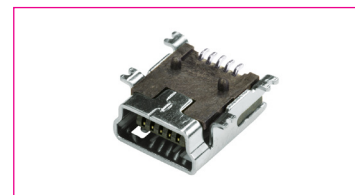

**MATERIAL:**


Material (Terminal):	phosphor bronze, tin plated
Material (Housing):	brass, nickel plated
Flammability Class:	UL 94 V-0
Material (Insulation):	LCP
Material (Contact Area):	phosphor bronze, gold plated

**HANDLING:**

Packaging: taped with foil

**TOLERANCE:**

.X:	± 0.25
.XX:	± 0.20

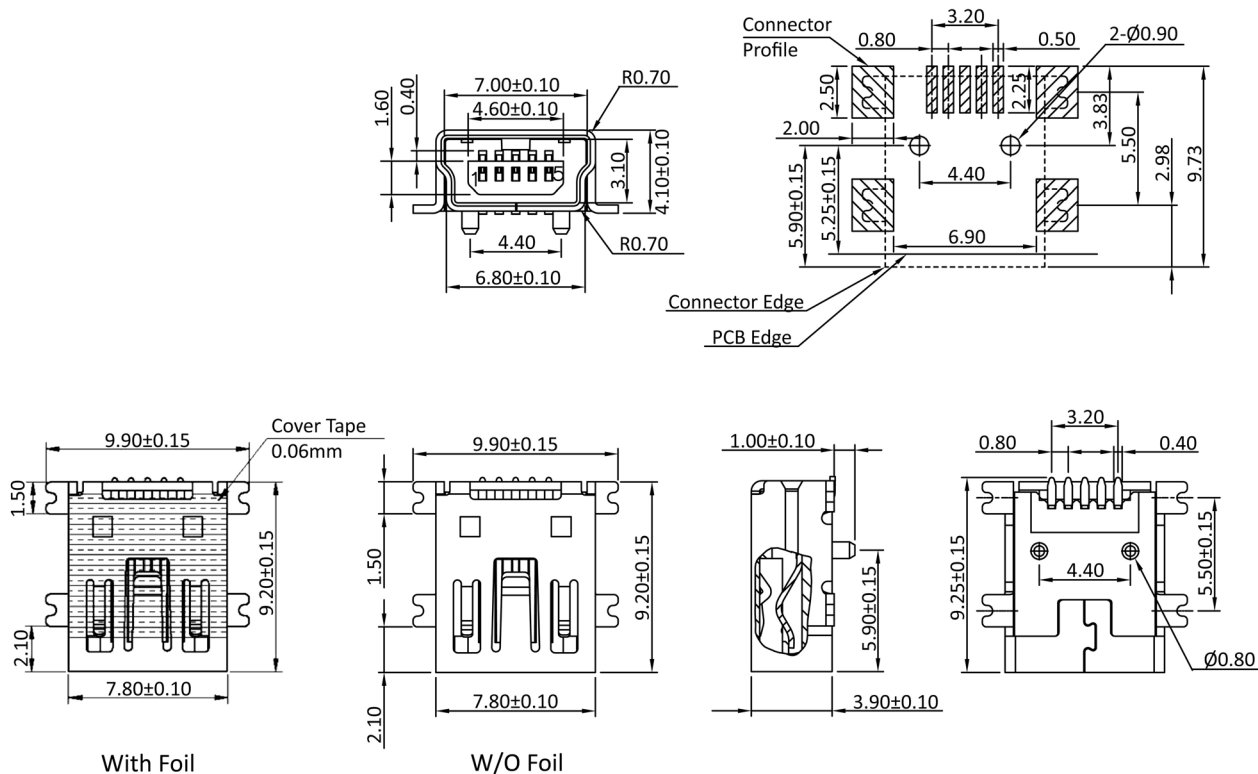

**Order Information**

Identifier: <b>MUB</b>	Special: <b>#</b>	Version: <b>B5SMD</b>
Socket 5 poles angled	1: with foil 2: w/o foil	B5SMD