

**Power Cables
IEC C13**

**Plug Great Britain BS 1363 to Straight
IEC Socket C13**




SPECIFICATION:

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	6.5 mm
Strands Cross Section:	0.75 mm ²
Strands Layout:	42 x 0.148 mm
Core Diameter:	2.3 mm



MATERIAL:

Type: H05VV-F3G

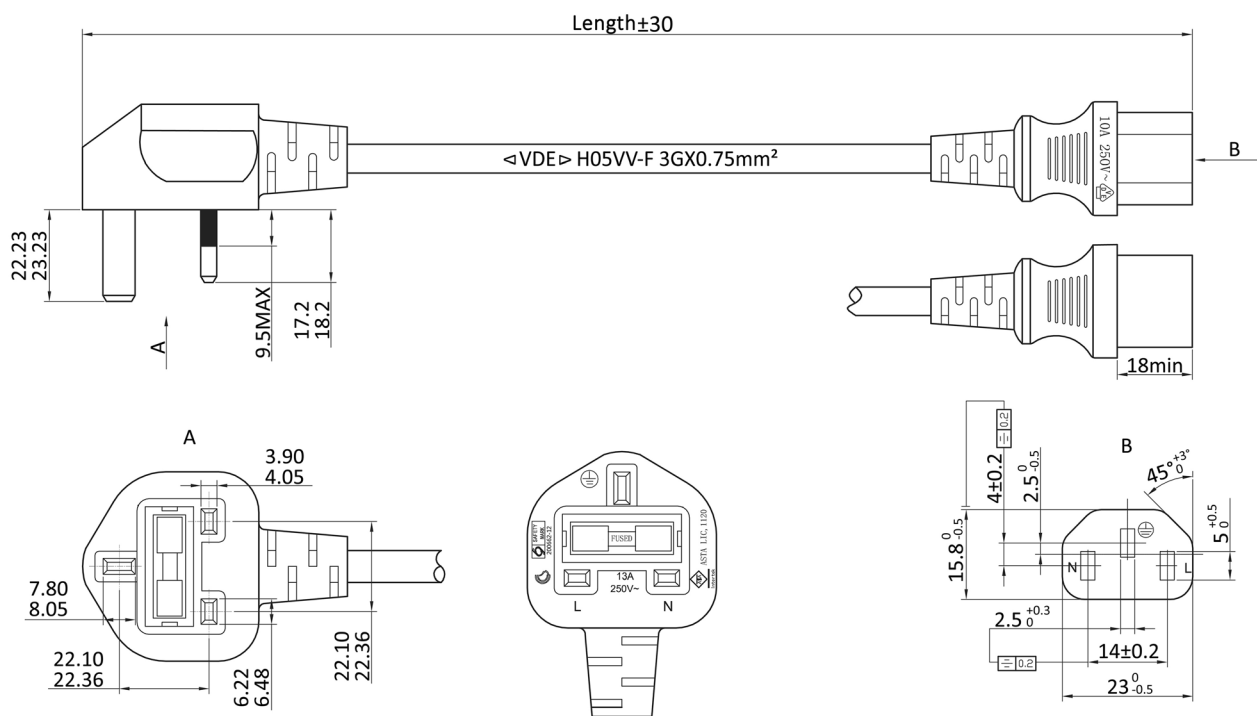

Order Information

Identifier: NKGB	Length: 2	Colour: SW
Power cable GB angled to straight IEC socket	2.0 m	black