

Pin Headers Pitch 2.54 mm SMT angled

Double row




SPECIFICATION:

Operating Current (Nom.): 3 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 1,000 Vac

SMT

MATERIAL:

Material (Terminal): copper alloy
 Material (Insulation): nylon 6T
 Flammability Class: UL 94 V-0
 Material (Contact Area): copper alloy, gold plated


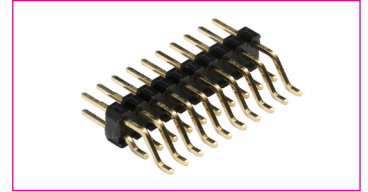


HANDLING:



Processing: reflow soldering

TOLERANCE:

.X: ± 0.25
 .XX: ± 0.20

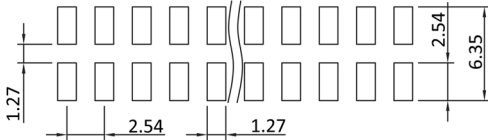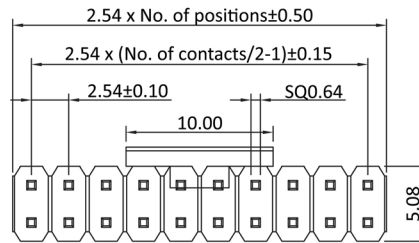

Recommended PCB Layout
(PCB Tolerance ± 0.05)

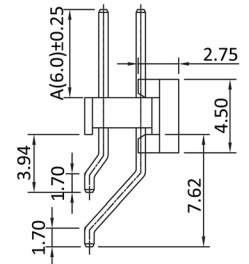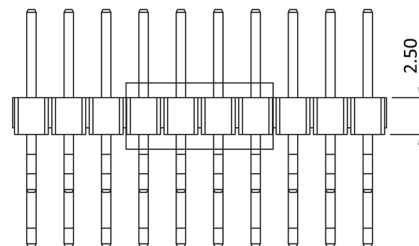

Order Information

Identifier:	No. of Contacts:	Contact Plating:	Length:	Packing:
PHS1D	#	G	B	T
SMT Pin header pitch 2.54 mm double row angled	4: 2 x 2	gold plated *	A=6.0 *	tube *
	6: 2 x 3			
	8: 2 x 4			
	:			
	80: 2 x 40			